



XAGA® 1000 Copper Closure, pressurized, heat shrink, 720 mm sheath opening, 200 mm splice bundle diameter

- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems
- Full range of closures to suit all copper cable sizes

## Product Classification

<b>Product Type</b>	Pressurized heat shrink closure
<b>Product Series</b>	XAGA 1000
<b>Regional Availability</b>	EMEA
<b>Product Brand</b>	XAGA®


## General Specifications

<b>Application</b>	For use with Polyethylene and metal jacketed cables
<b>Branch-off Clip</b>	To be ordered separately
<b>Cable Capacity, maximum</b>	4
<b>Color</b>	Black
<b>Includes</b>	Abrasive strip   Aluminum closing strip   Aluminum foil   Cleaning tissues   Flexible stainless steel channels   Heatshrinkable sleeve   Metal canister   Shield continuity wire   Underclips   Valve hardware
<b>Package, quantity</b>	1
<b>Packaging Type</b>	Bag   Carton
<b>Single Cable Diameter, minimum</b>	65.00 mm   2.56 in
<b>Splice Bundle Diameter, maximum</b>	200.00 mm   7.87 in

## Dimensions

<b>Sheet Opening, nominal</b>	720.00 mm   28.35 in
-------------------------------	----------------------

## Dimension Drawing

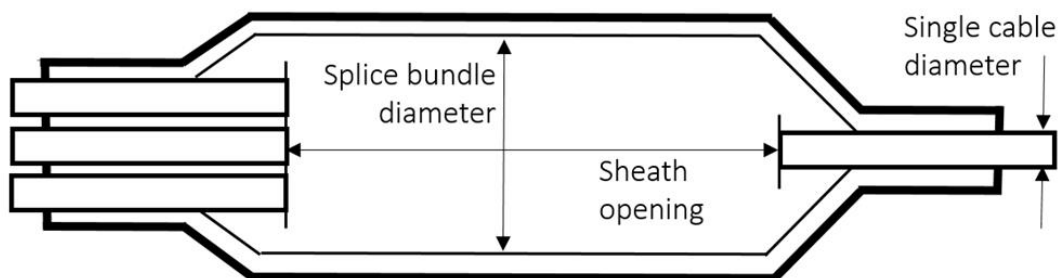

**Dimension Drawing** Used as an image placeholder

## Mechanical Specifications

<b>Cable Sealing Type</b>	Hotmelt adhesive
<b>Closure Style</b>	In-line
<b>Material Type</b>	Fiber-reinforced multi-layer sealing sleeve
<b>Mount Type</b>	Duct   Manhole
<b>Splice Protection Type</b>	Metal canister with valve

## Environmental Specifications

**Environmental Space** Aerial | Below ground | Buried

## Regulatory Compliance/Certifications

**Agency**  
RoHS 2011/65/EU

**Classification**  
Compliant

