



OWB Fiber Optic Wall Mount Fiber Box, 2 SC/UPC adapters, fusing splice, 8 fuse splice protectors, no splitters

- Compact sized with multiple cable entry point options
- Used as a premises connection device in FTTH networks
- Easy access via the combined hinge + latch design
- High sealing rate, UV resistant and UL compliant
- Slack storage (3 mtr) for drop- and premise connection cable

Product Classification

Product Type	Fiber wall box
Product Series	OWB
Regional Availability	North America


General Specifications

Application	For cables with outer diameter 3 x 5.4 mm: 1 on top + 1 on bottom For cables with outer diameter up to 10 mm: each on both sides For cables with outer diameter up to 5 mm: 1 on rear + 4 on bottom
Enclosure Color	Gray
Functionality	Patching Splicing
Includes	Grommets
Interface Feature, input	APC
Interface, input	SC
Package, quantity	1
Packaging Type	Box Carton
Port Capacity, maximum	4
Port, quantity	2
Splicing Capacity, maximum	8

Dimensions

Depth	71.88 mm 2.83 in
Height	209.80 mm 8.26 in
Width	173.74 mm 6.84 in

Dimension Drawing

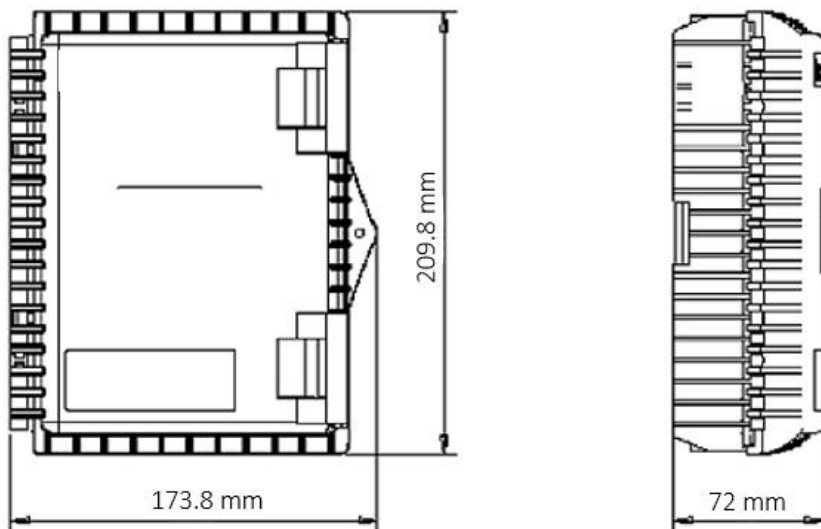

Dimension Drawing

Used as an image placeholder

Mechanical Specifications

Access	Front
Enclosure Material Type	LSZH thermoplastic
Front Cover Type	Hinged with latches
Lock Type	Ski latch and screw
Mount Type	Wall

Optical Specifications

Fiber Mode	Singlemode
Insertion Loss, Terminal Connector, maximum	0.10 dB

Environmental Specifications

Environmental Space	Outdoor
Flammability Rating	UL 94 V-0
Installation Temperature	-5 °C to +45 °C (+23 °F to +113 °F)
Qualification Standard	IEC 60529, IP65
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

