

F1A-XMHM-3M-CHT



FSJ1-50A SureFlex® Jumper with interface types NEX10 Male and 4.3-10 Male, 3m

- **WARNING: DO NOT MATE WITH 4.1-9.5 DIN**

Product Classification

Product Series FSJ1-50A
Product Type Wireless transmission cable assembly

General Specifications

Body Style, Connector A Straight
Body Style, Connector B Straight
Interface, Connector A Nex10 Male
Interface, Connector B 4.3-10 Male
Length 3.000 m | 9.843 ft
Nominal Size 1/4 in
Specification Sheet Revision Level A


Electrical Specifications

3rd Order IMD at Frequency -155 dBc @ 1,800 MHz
3rd Order IMD Test Method Two +43 dBm carriers

Environmental Specifications

Immersion Test Method Meets IEC 60529:2001, IP68 in mated condition

Jumper Assembly Sample Label

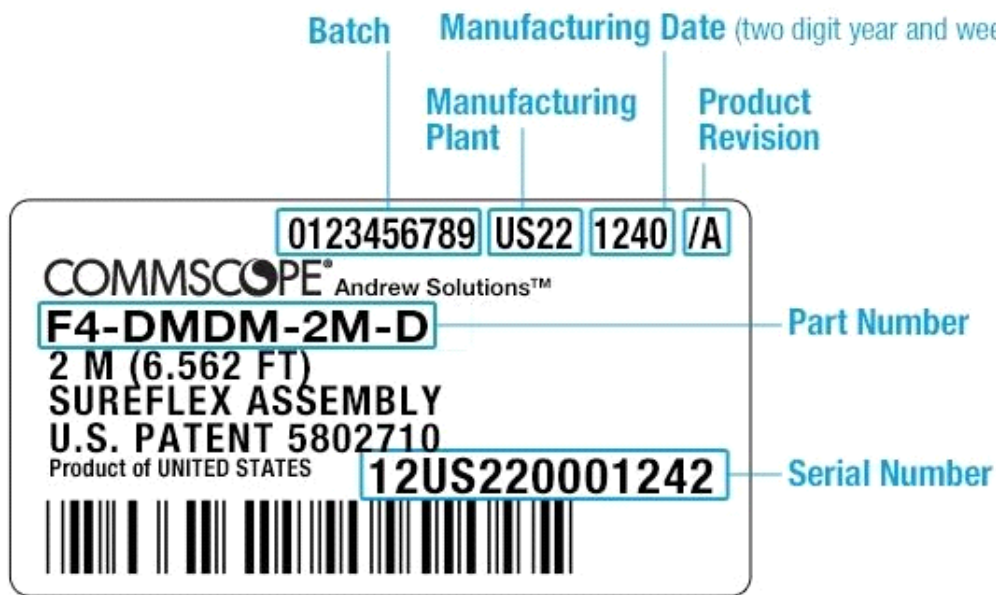

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
698–960 MHz	1.07	30.00
1700–2200 MHz	1.08	28.00
2500–2700 MHz	1.11	26.00
3400–3800 MHz	1.22	20.00

Regulatory Compliance/Certifications

Agency

RoHS 2011/65/EU
China RoHS SJ/T 11364-2014

Classification

Compliant by Exemption
Above Maximum Concentration Value (MCV)

