

PTS1P-XMHM-3-P



PTS1-50-P SureFlex® Jumper with interface types NEX10 Male and 4.3-10 Male , 3 ft

- **WARNING: DO NOT MATE WITH 4.1-9.5 DIN**

Product Classification

Product Series PTS1-50-P
Product Type Wireless transmission cable assembly

General Specifications

Body Style, Connector A Straight
Body Style, Connector B Straight
Interface, Connector A Nex10 Male
Interface, Connector B 4.3-10 Male
Length 0.914 m | 3.000 ft
Nominal Size 1/4 in
Specification Sheet Revision Level A


Electrical Specifications

3rd Order IMD Static -159.00 dBc | -116.00 dBm
3rd Order IMD Static Test Method Two +43 dBm carriers

Environmental Specifications

Immersion Test Method Meets IEC 60529:2001, IP68 in mated condition

Jumper Assembly Sample Label

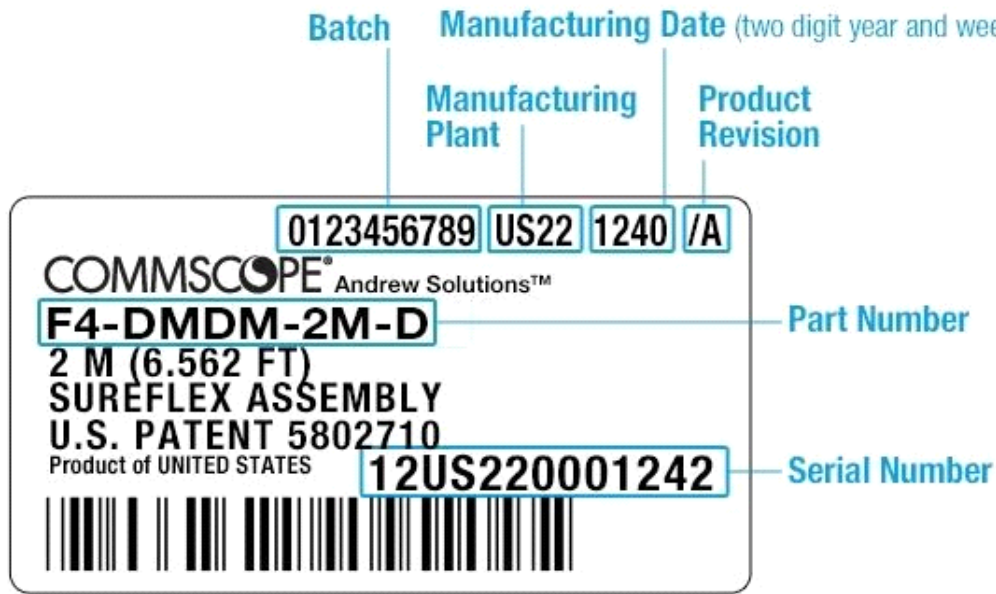

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
698–960 MHz	1.07	30.00
1700–2200 MHz	1.08	28.00
2500–2700 MHz	1.11	26.00
3400–3800 MHz	1.22	20.00

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2011/65/EU	Compliant by Exemption
China RoHS SJ/T 11364-2014	Above Maximum Concentration Value (MCV)

