


# UNGQXLUTR

## Base Product

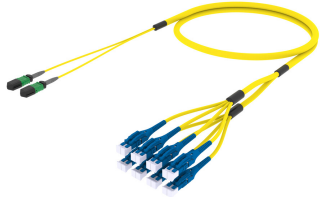

Singlemode MPO8 APC pinned to LC/UPC Uniboot Ruggedized fanout Cable, 16-Fiber, Dual Rated (OFNR/LSZH), 8 fiber PmP 2.0 mm

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Ruggedized fanout

### Product Brand

Propel | SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications


<b>Connector A, quantity</b>	2
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	16
<b>Color, boot B</b>	Blue
<b>Color, connector B</b>	Blue
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-08/APC Male
<b>Interface, Connector B</b>	LC/UPC
<b>Interface Feature, connector B</b>	Uniboot
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	16

## Dimensions

# UNGQXLUTR

<b>Breakout Length</b>	22 in
<b>Cable Assembly Length Range (m)</b>	3 – 305
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

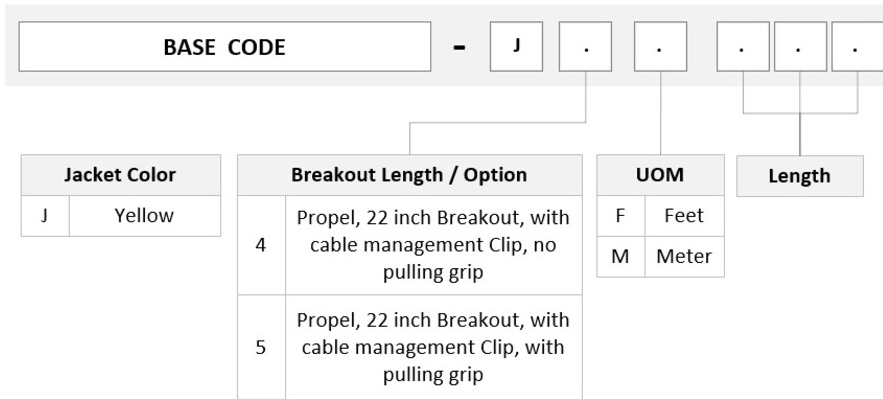

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

# UNGQXLUTR

---

UK-ROHS

Compliant/Exempted



## Included Products

- |                                       |   |                                                                                                                                                                                       |
|---------------------------------------|---|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| 760245570<br>N-016-MP-8G1-F08YL/20T/D | - | Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 16 fiber with 8 fiber 2.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating |
| 860658160                             | - | LC/UPC Uniboot Connector, Singlemode, Blue                                                                                                                                            |
| 860659022                             | - | MPO-08, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm                                                                                                                                  |