


A3GMPPMPCP

Base Product

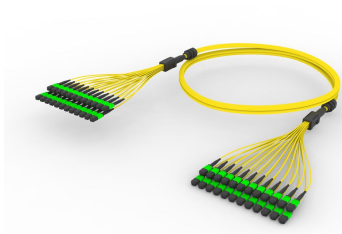

Ultra Low Loss (ULL) Singlemode MPO12 (Non-Pinned) to MPO12 (Non-Pinned) Pre-terminated Trunk Cable, 12 fiber PmP 2.0mm / LSZH B2ca, 288-Fiber

Product Classification

Regional Availability	Europe Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	MPO-12/APC Female
Jacket Color	Yellow
Polarity	Method A
Fibers per Subunit, quantity	12
Total Fibers, quantity	288

Dimensions


Cable Assembly Length Range (m)	3 – 999
--	---------

A3GMPMPCP

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

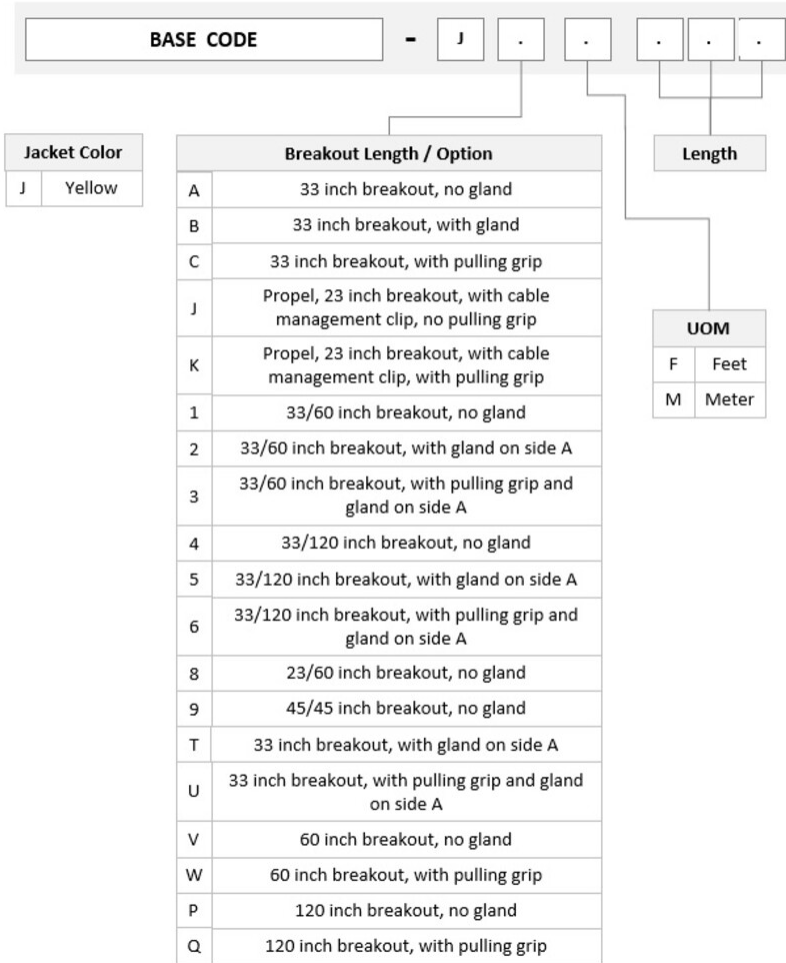

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

A3GMPCP

Environmental Space

Indoor | Low Smoke Zero Halogen (LSZH)

Included Products

- 760249612
N-288-MP-8G1-F12YL/20T/B2 - Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 288 fiber with 2.0 mm Subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860638318 - MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm