


FAVLCUCOC

Base Product

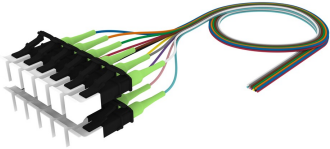

LazrSPEED® 550 WideBand LC/UPC to Unconnectorized, Fiber Pigtail, 0.9 mm Tight Buffer, 12-Fiber Kit Blue - Aqua (1-12)

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration


General Specifications

Color, boot A	Lime green
Color, connector A	Black
Interface, Connector A	LC/UPC
Total Fibers, quantity	12

Dimensions

Cable Assembly Length Range (m)	1 – 20
Cable Assembly Length Range (ft)	1 – 66

Ordering Tree

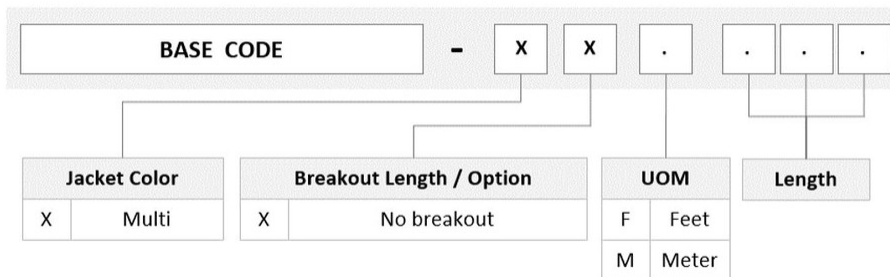

Mechanical Specifications

FAVLCUCOC

Cable Retention Strength, maximum 1.00 lb @ 0 ° | 1.00 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM5, LazrSPEED®
Insertion Loss, maximum, connector A 0.24 dB
Return Loss, minimum, connector A 27 dB

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Unrated

Included Products

- 860657285 – LC/PC Connector, Multimode, Lime
- CS-5G-TB – LazrSPEED® OM5 WideBand Multimode Fiber