

IFEB20, Indoor Fiber Optic Wall mount Enclosure, Splice Only, Single Element Slim trays(12) Smouv, No cable Seals, RAL 9010

- Compact, wall mountable fiber enclosures for indoor use
- Specifically designed for fast FTTH deployment and easy customer connection
- Configurable as splice only or connectorized solution
- Multiple and modular wrap around cable port sealing options to suit a wide range of cables
- Easy intergration of 900µm connectorised or 250µm splice splitters
- Single Element (SE), Single Slim Element (SLE) or Single Circuit (SC) tray options - Smouv and ANT
- Powered by NOVUX™

Product Classification

Regional Availability	EMEA
Portfolio	CommScope®
Product Type	Fiber wall box
Product Series	IFEB-20

General Specifications


Functionality	Splicing
Access	Front
Adapter Ports, quantity	0
Cable Ports, quantity	0
Drop Port, quantity	0
Enclosure Color	Pure White (RAL 9010)
Front Cover Type	Snap-on cover
Interface	Splicing only
Pigtails Included, quantity	0
Splice Tray Construction	SLE (Slim element tray for up to 12 primary coated fibers)
Splicing Capacity, maximum	144
Splicing Type	SMOUV

Dimensions

Height	270 mm   10.63 in
Height, with cover	348 mm   13.701 in


Width	213 mm   8.386 in
Depth	87 mm   3.425 in

Dimension Drawing

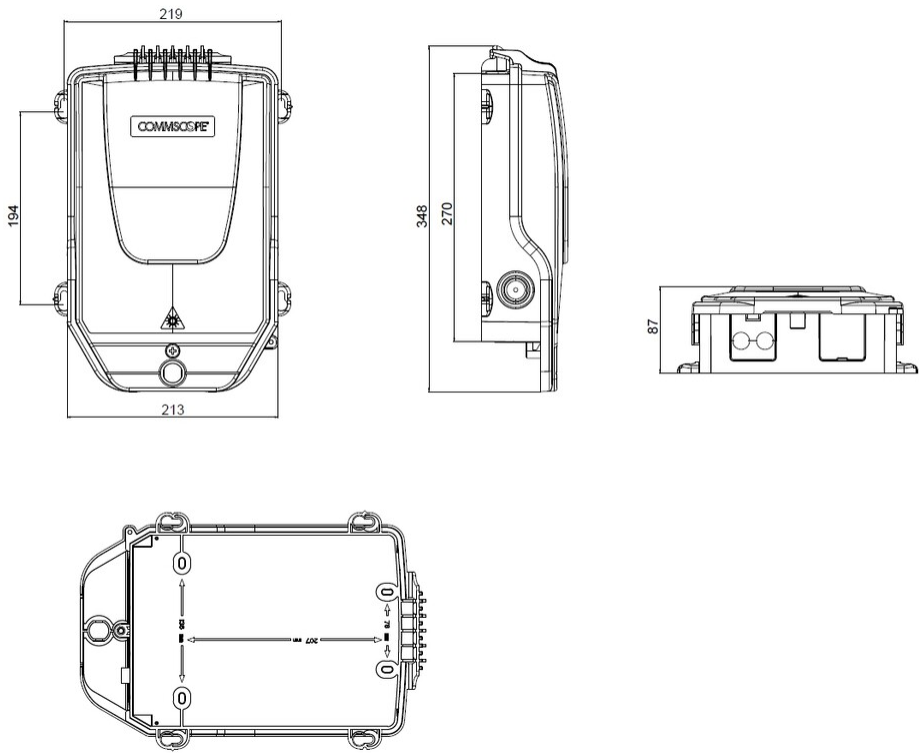

Ordering Tree

760259787 | IFEB-20WAN000C12SNNNNN000

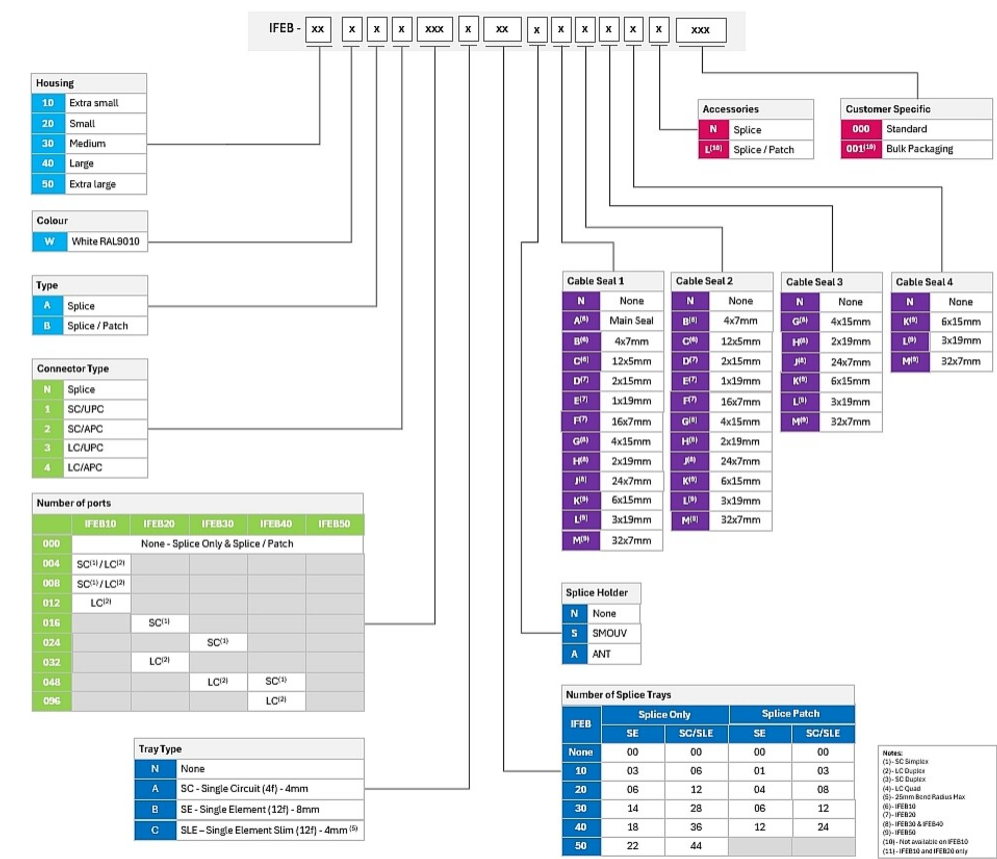

CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

