

IFEB20, Indoor Fiber Optic Wall mount Enclosure, Splice Only, Single Element Slim trays(12) Smouv, Feeder cable seal 2x15 and 16x7mm drop seal, RAL 9010

- Compact, wall mountable fiber enclosures for indoor use
- Specifically designed for fast FTTH deployment and easy customer connection
- Configurable as splice only or connectorized solution
- Multiple and modular wrap around cable port sealing options to suit a wide range of cables
- Easy intergration of 900µm connectorised or 250µm splice splitters
- Single Element (SE), Single Slim Element (SLE) or Single Circuit (SC) tray options - Smouv and ANT
- Powered by NOVUX™

Product Classification

Regional Availability	EMEA
Portfolio	CommScope®
Product Type	Fiber wall box
Product Series	IFEB-20

General Specifications


Functionality	Splicing
Access	Front
Adapter Ports, quantity	0
Cable Ports, quantity	2
Drop Port, quantity	16
Enclosure Color	Pure White (RAL 9010)
Front Cover Type	Snap-on cover
Interface	Splicing only
Pigtails Included, quantity	0
Splice Tray Construction	SLE (Slim element tray for up to 12 primary coated fibers)
Splicing Capacity, maximum	144
Splicing Type	SMOUV

Dimensions

Height	270 mm 10.63 in
--------	-------------------


Height, with cover	348 mm 13.701 in
Width	213 mm 8.386 in
Depth	87 mm 3.425 in

Dimension Drawing

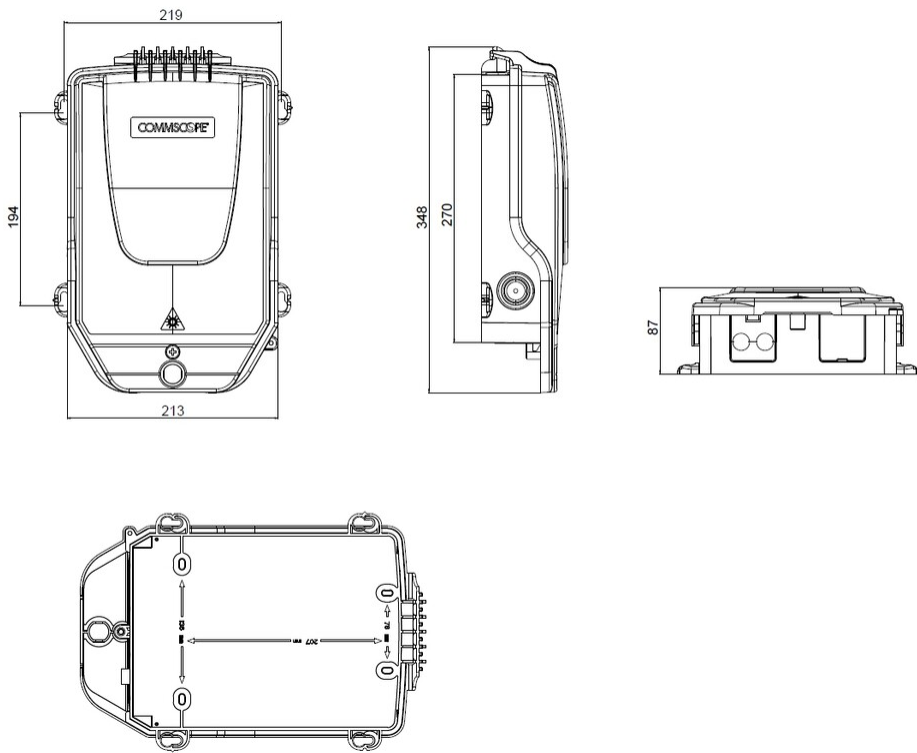

Ordering Tree

760259786 | IFEB-20WAN000C12SDFNNN000

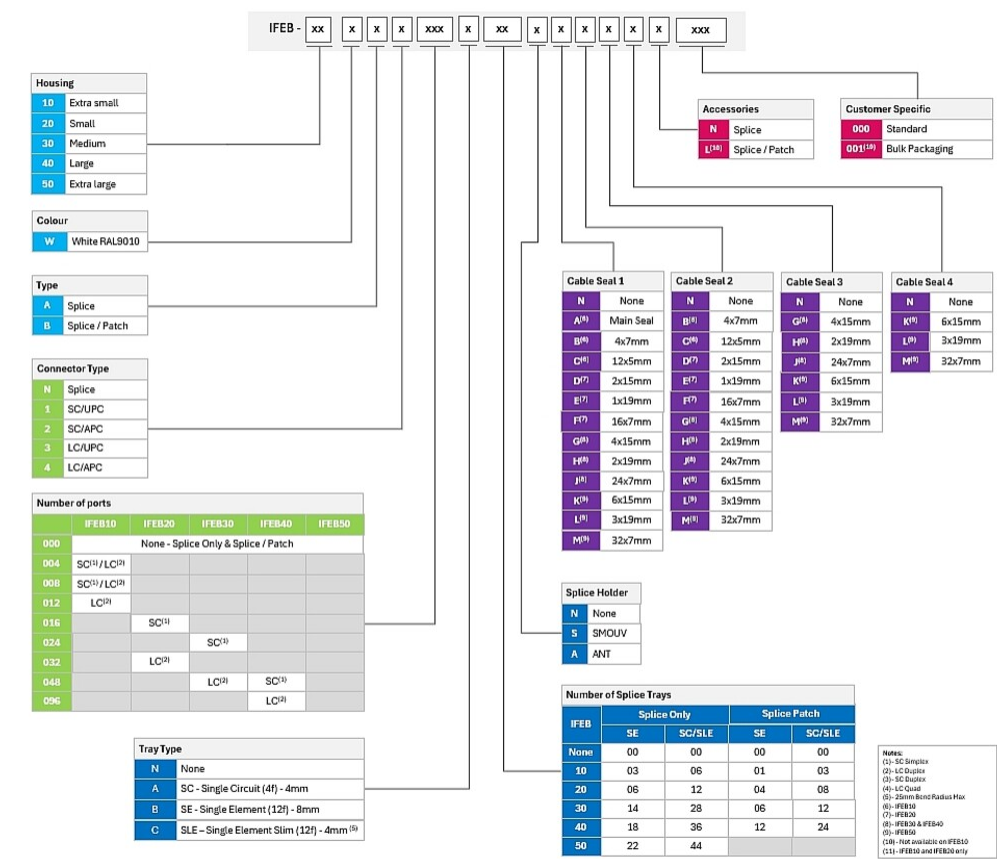

Environmental Specifications

Installation temperature	-5 °C to +45 °C (+23 °F to +113 °F)
Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor
Flammability Rating	UL 94 V-0
Qualification Standards	IEC 60529, IP50 IEC 61753-1 Ed.2 2018 - Category C

Packaging and Weights

Included	Box (1) Drop Seal, 16x7 (1) Feeder Seal, 2x15 (1) SLE Smouv trays (12)
Packaging quantity	1
Packaging Type	Box

Regulatory Compliance/Certifications

Agency	Classification
--------	----------------

CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

