



IFEB40, Indoor Fiber Optic Wall mount Enclosure, Splice Only, Single Element Slim trays(36) Smouv, No cable Seals, RAL 9010

- Compact, wall mountable fiber enclosures for indoor use
- Specifically designed for fast FTTH deployment and easy customer connection
- Configurable as splice only or connectorized solution
- Multiple and modular wrap around cable port sealing options to suit a wide range of cables
- Easy intergration of 900µm connectorised or 250µm splice splitters
- Single Element (SE), Single Slim Element (SLE) or Single Circuit (SC) tray options - Smouv and ANT
- Powered by NOVUX™

Product Classification

Regional Availability	EMEA
Portfolio	CommScope®
Product Type	Fiber wall box
Product Series	IFEB-40

General Specifications

Functionality	Splicing
Access	Front
Adapter Ports, quantity	0
Cable Ports, quantity	0
Drop Port, quantity	0
Enclosure Color	Pure White (RAL 9010)
Front Cover Type	Snap-on cover
Interface	Splicing only
Pigtails Included, quantity	0
Splice Tray Construction	SLE (Slim element tray for up to 12 primary coated fibers)
Splicing Capacity, maximum	432
Splicing Type	SMOUV


Dimensions

Height	425 mm 16.732 in
Height, with cover	500 mm 19.685 in

760259798 | IFEB-40WAN000C36SNNNNN000


Width	295 mm 11.614 in
Depth	145 mm 5.709 in

Dimension Drawing

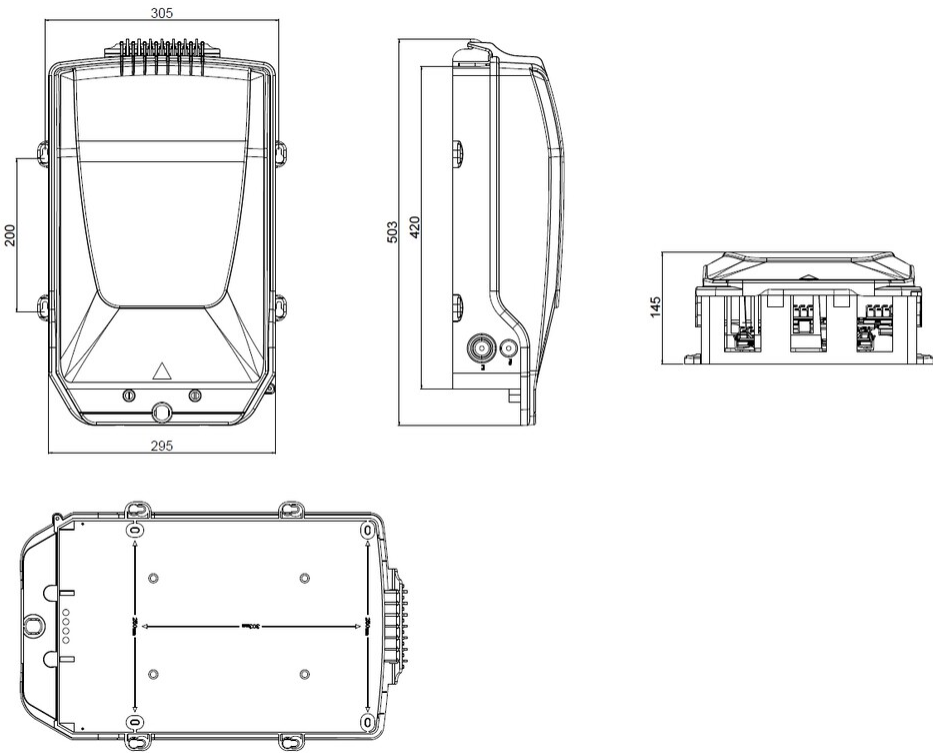

Ordering Tree

760259798 | IFEB-40WAN000C36SNNNNNN000

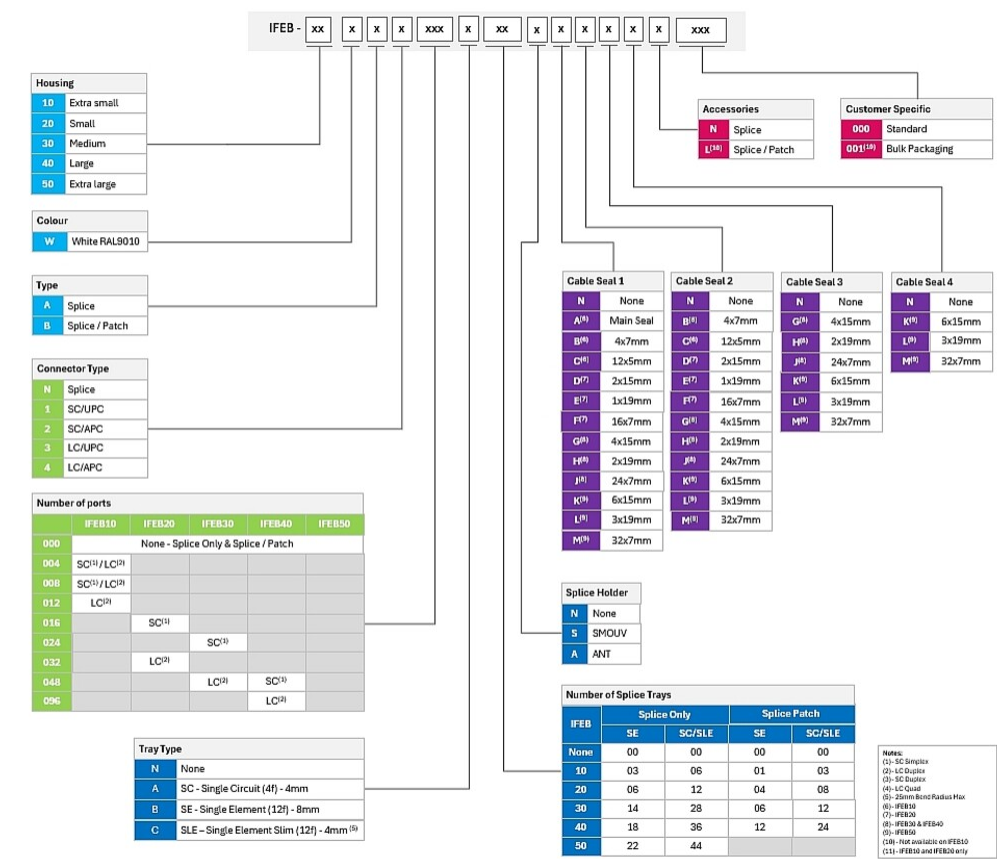

760259798

|

IFEB-40WAN000C36SNNNNN000

CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

