


OM412D42YAE2XN2X0000

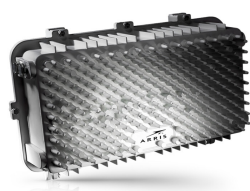

Opti Max™ 1.2 GHz Deep OM4120 Optical Node, 4x4 HFC Segmentable

- *Product complies with the Build America, Buy America Act (BABAA) requirements of the Infrastructure Investment and Jobs Act of 2021 (Pub. L. 117- 58, §§ 70901-70953), or is the subject of a waiver approved by the Secretary of Commerce or designee. Compliance requirements and waiver applicability vary based on government funding program. Check the laws and regulations for your specific program.

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Optical node platform
Product Series	OM4120
Government Requirements	Build America Buy America (BABA) compliant*

General Specifications

Location of Manufacturing	Waived per BABA waiver for BEAD Program
---------------------------	-----------------------------------------

Electrical Specifications

Input Voltage Range, ac	44–90 V
-------------------------	---------

Environmental Specifications

Operating Temperature	-40 °C to +60 °C (-40 °F to +140 °F)
Relative Humidity	5%–95%, non-condensing

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

