


CX3450014 | 150T135P3840JCASS COEX

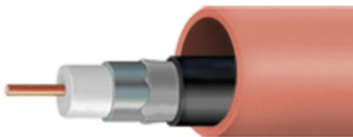

ConQuest® Cable in Conduit, 1 1/2 in, SDR 13.5, terracotta (P3® 840 JCASS)

Product Classification

Product Type	Coaxial cable-in-conduit
Product Brand	ConQuest®
Product Series	840 Series

General Specifications

Cable Type	840 series
Cable-In-Conduit Type	P3® in duct
Color	Terracotta
Conduit Type	Non-toneable
Wall Type	Smooth

Dimensions

Length	731.52 m 2400 ft
Wall Thickness Designation	SDR 13.5
Nominal Size	1-1/2 in

Packaging and Weights

Weight, net	858.671 kg/km 577 lb/kft
-------------	----------------------------

Included Products

5333503 P3® 840 JCASS	–	75 Ohm P3® Trunk and Distribution Cable, black PE jacket, flooded for underground
CX3499999 150T135 EMPTY DUCT COEX	–	ConQuest® Empty Conduit, 1 1/2 in, SDR 13.5, terracotta