


760243590 | PNL-BK-024-KHB-LC02-RO-NS

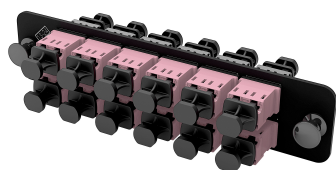

Adapter Pack, Black, 1000-Type, with 12 duplex keyed hybrid LC adapters, rose, no shutter

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Fiber adapter pack |
| Product Series | 1000-style |

General Specifications

| | |
|------------------------------------|---|
| Application | Used in conjunction with SD Panels Used in conjunction with panels and enclosures (rack, wall, and floor mount) that accept 1000 style panels |
| Adapter Color | Rose |
| Adapter Cutout, quantity | 12 |
| Adapters, quantity | 12 |
| Body Style | Duplex |
| Interface | LC/UPC |
| Interface Feature | Keyed Hybrid |
| Pigtails Included, quantity | 0 |
| Shuttered | No |
| Total Ports, quantity | 24 |

Optical Specifications

| | |
|-------------------|------------------------|
| Fiber Mode | Multimode Singlemode |
|-------------------|------------------------|

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Above maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |

UK-ROHS

Compliant/Exempted

