


CK3081-000 | FIST-GPST-12-IASC-2

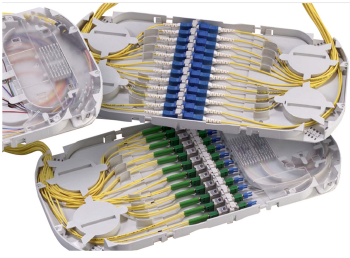

FIST GPST Fiber Patch/Splice Tray, 12 ports, SC/UPC, singlemode, preterminated with pigtails, SMOUV splice chip, 19 in, gray, left patch cord routing

OBSOLETE

This product was discontinued on: November 13, 2018

Product Classification

Regional Availability	EMEA
Product Type	Fiber patch/splice tray
Product Brand	FIST®
Product Series	FIST-GPST

General Specifications

Functionality	Patching Splicing
Color	Gray
Interface, front	SC/UPC
Patch Cord Entry Location	Front, left side
Splicing Type	Heat shrink, single fiber fusion
Total Ports, quantity	12

Dimensions

Height	18 mm 0.709 in
Width	355 mm 13.976 in
Depth	190 mm 7.48 in

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-5 °C to +45 °C (+23 °F to +113 °F)
------------------------------	-------------------------------------

CK3081-000 | FIST-GPST-12-IASC-2

Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)
Relative Humidity Up to 93%, non-condensing

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

