


CS8007-000 | FIST-GPST-12-IAFC-2

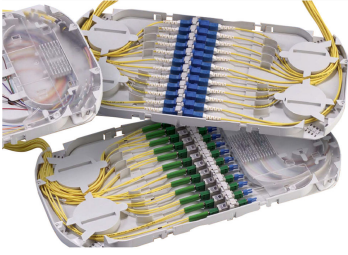

FIST GPST Fiber Termination/Splice Tray, 12 ports, FC/UPC, singlemode, preterminated with pigtails, SMOUV splice chip, 19 in, gray, left patch cord routing

OBSOLETE

This product was discontinued on: **March 1, 2018**

Product Classification

| | |
|------------------------------|-------------------------|
| Regional Availability | EMEA |
| Product Type | Fiber patch/splice tray |
| Product Brand | FIST® |
| Product Series | FIST-GPST |

General Specifications

| | |
|----------------------------------|----------------------------------|
| Functionality | Patching Splicing |
| Color | Gray |
| Interface, front | FC/UPC |
| Patch Cord Entry Location | Front, left side |
| Splicing Type | Heat shrink, single fiber fusion |
| Total Ports, quantity | 12 |

Dimensions

| | |
|---------------|--------------------|
| Height | 18 mm 0.709 in |
| Width | 355 mm 13.976 in |
| Depth | 190 mm 7.48 in |

Optical Specifications

| | |
|-------------------|------------|
| Fiber Mode | Singlemode |
|-------------------|------------|

Environmental Specifications

Operating Temperature -5 °C to +45 °C (+23 °F to +113 °F)

Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)

Relative Humidity Up to 93%, non-condensing

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|--|
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |