


CZ7625-000 | FIST-GPST-12-AAL1-2C

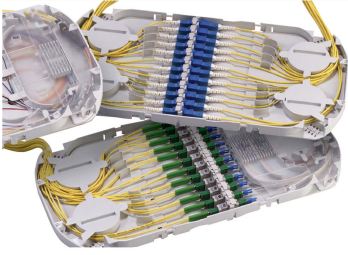

FIST GPST Fiber Patch Tray, 24 ports, LC/UPC, singlemode, 19 in, gray, left/right patch cord routing

Product Classification

Regional Availability	EMEA
Product Type	Fiber patch tray
Product Brand	FIST®
Product Series	FIST-GPST

General Specifications

Functionality	Patching
Color	Gray
Interface, front	LC/UPC
Patch Cord Entry Location	Front, left side Front, right side
Patching Capacity, maximum	24
Splicing Capacity, maximum	0
Total Ports, quantity	24

Dimensions

Height	18 mm 0.709 in
Width	355 mm 13.976 in
Depth	190 mm 7.48 in

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-5 °C to +45 °C (+23 °F to +113 °F)
------------------------------	-------------------------------------

CZ7625-000 | FIST-GPST-12-AAL1-2C

Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)

Relative Humidity Up to 93%, non-condensing

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

