

FMT-DRT060A00-A24P



FMT Fiber Termination Panel, with sliding tray, 24 LC/UPC, multimode, 1RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FMT

General Specifications


Functionality	Patching
Body Style	Symmetrical
Color	Black + Putty white (front)
Interface, front	LC/UPC
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Total Ports, quantity	24

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in

Ordering Tree

FMT-DRT060A00-A24P

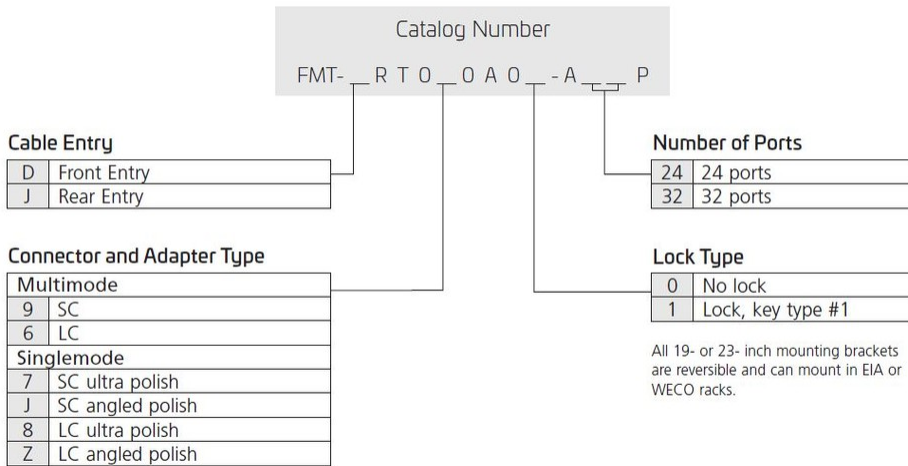

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Multimode

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant/Exempted

