

FMT-GBS000000-F00P

FMT Fiber Storage Panel, with sliding tray and storage spools, 2RU, 19 in, putty white



Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber storage panel
Product Series	FMT

General Specifications


Functionality	Slack storage
Body Style	Symmetrical
Color	Black
Color, front	Putty white
Growth Configuration	Unloaded
Patching Capacity, maximum	0
Rack Type	EIA 19 in EIA 23 in
Rack Units	2
Shelf Movement	Sliding
Splicing Capacity, maximum	0

Dimensions

Height	88.9 mm 3.5 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in

Ordering Tree

FMT-GBS000000-F00P

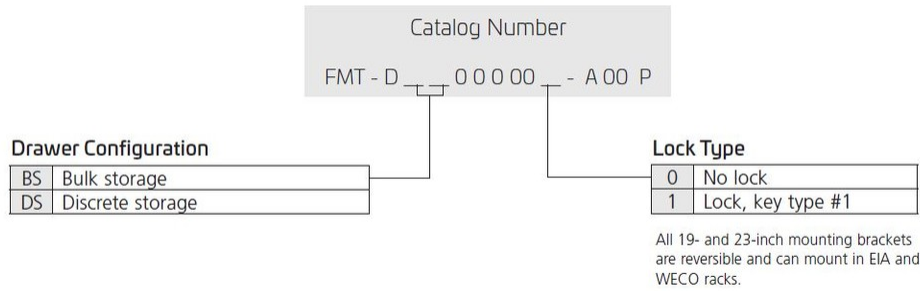

Material Specifications

Finish	Powder coated
Material Type	Steel

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

