

FMT-GTL070U20-A48P



FMT Fiber Termination/Splice Panel, with sliding tray, 48 SC/UPC, singlemode, 2RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FMT

General Specifications


Functionality	Patching Splicing
Body Style	Symmetrical
Color	Black + Putty white (front)
Interface, front	SC/UPC
Rack Type	EIA 19 in EIA 23 in
Rack Units	2
Shelf Movement	Sliding
Total Ports, quantity	48

Dimensions

Height	88.9 mm 3.5 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in

Ordering Tree

FMT-GTL070U20-A48P

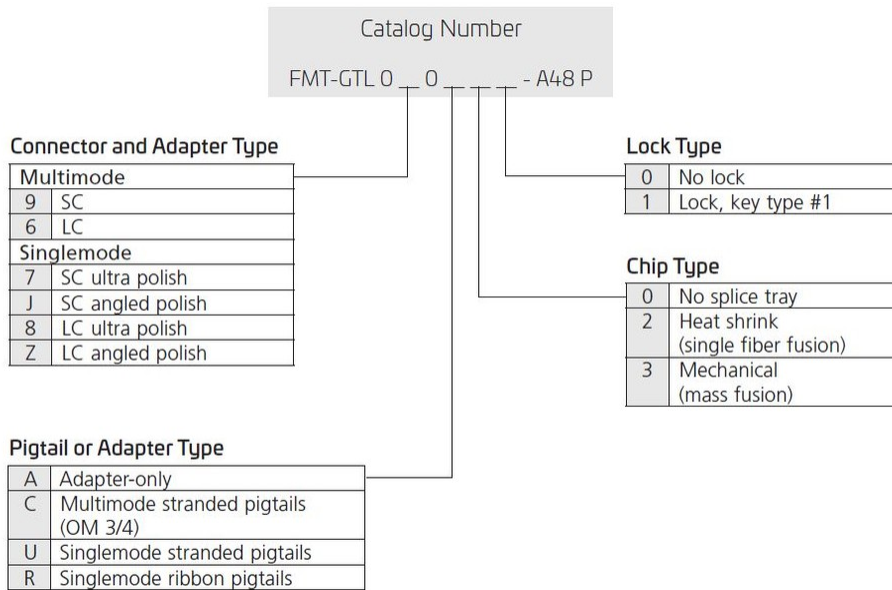

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant/Exempted

