

FMT-JN2A70160-A24P

FMT Fiber Termination Panel, 24 SC/UPC, singlemode, 1RU, 19 in, putty white, pre-terminated with IFC cable, 16 meters, stub tail at far end



Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel, with IFC cable
Product Series	FMT

General Specifications


Functionality	Patching
Body Style	Symmetrical
Cable Stub Type	IFC
Color	Black
Color, front	Putty white
Interface, front	SC
Interface Feature, front	Standard
Interface, rear	Stub tail
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Total Ports, quantity	24

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in
Cable Stub Length	16 m 52.493 ft

FMT-JN2A70160-A24P

Ordering Tree

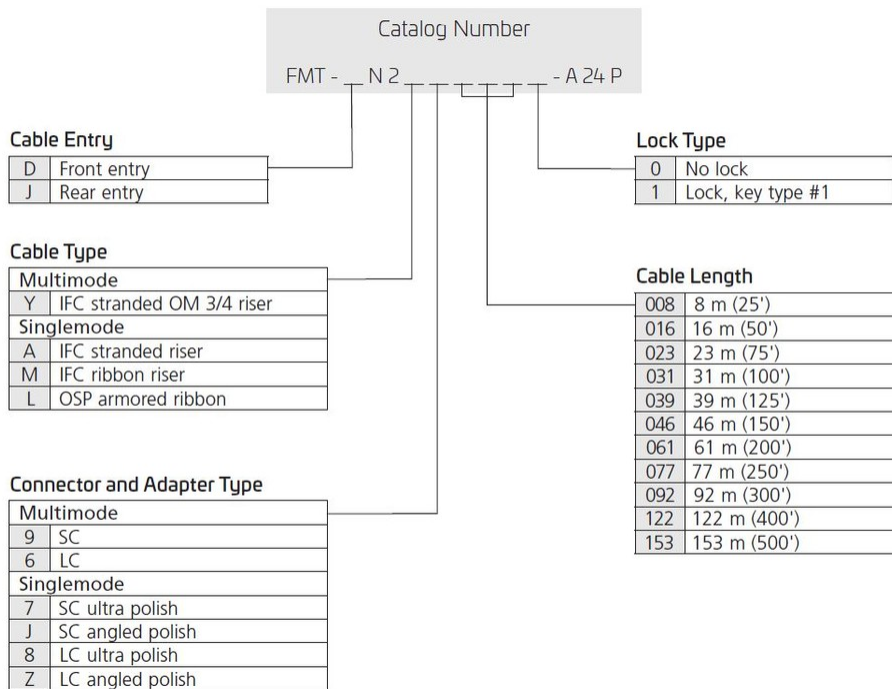

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted

FMT-JN2A70160-A24P

