

# FMT-JN2A70610-A24B

---



FMT Fiber Termination Panel, 24 SC/UPC, singlemode, 1RU, 19 in, black, pre-terminated with IFC cable, 61 meters, stub tail at far end

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch panel, with IFC cable
<b>Product Series</b>	FMT

## General Specifications


<b>Functionality</b>	Patching
<b>Body Style</b>	Symmetrical
<b>Cable Stub Type</b>	IFC
<b>Color</b>	Black
<b>Color, front</b>	Black
<b>Interface, front</b>	SC
<b>Interface Feature, front</b>	Standard
<b>Interface, rear</b>	Stub tail
<b>Rack Type</b>	EIA 19 in   EIA 23 in
<b>Rack Units</b>	1
<b>Shelf Movement</b>	Sliding
<b>Total Ports, quantity</b>	24

## Dimensions

<b>Height</b>	44.45 mm   1.75 in
<b>Width</b>	482.6 mm   19 in
<b>Depth</b>	279.91 mm   11.02 in
<b>Cable Stub Length</b>	61 m   200.131 ft

## Ordering Tree

# FMT-JN2A70610-A24B

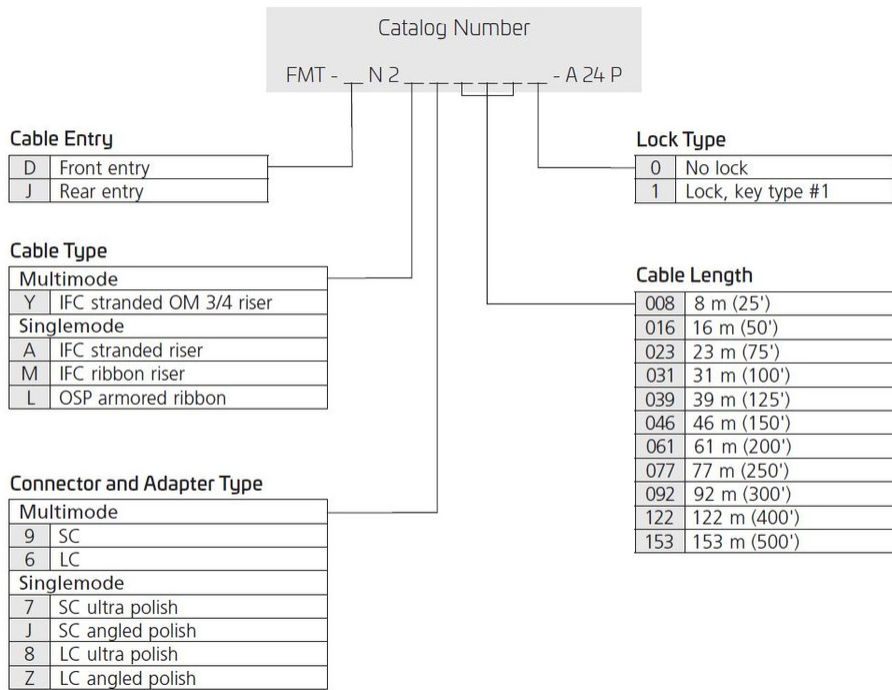

## Material Specifications

<b>Finish</b>	Powder coated
<b>Material Type</b>	Steel

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
-------------------	------------

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

