


PH3865-000 | FIST-GPST-8-AFN-N

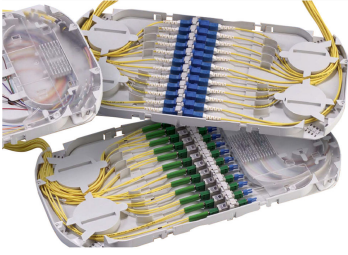

FIST GPST Fiber Termination/Splice Tray, 8/16 ports, no adapters, ANT splice chip, 19 in, gray, left patch cord routing

Product Classification

Regional Availability	EMEA
Product Type	Fiber patch/splice tray
Product Brand	FIST®
Product Series	FIST-GPST

General Specifications

Functionality	Patching Splicing
Color	Gray
Interface, front	Unloaded
Patch Cord Entry Location	Front, left side
Splicing Type	ANT, single fiber fusion
Total Ports, quantity	8

Dimensions

Height	18 mm 0.709 in
Width	355 mm 13.976 in
Depth	190 mm 7.48 in

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-5 °C to +45 °C (+23 °F to +113 °F)
Storage Temperature	-30 °C to +60 °C (-22 °F to +140 °F)

PH3865-000 | FIST-GPST-8-AFN-N

Relative Humidity Up to 93%, non-condensing

Packaging and Weights

Packaging quantity 1