


# NG4-MMDCM0L000

---

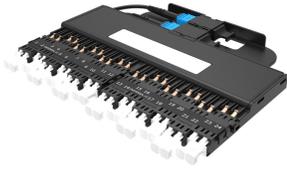

NG4access® MPO Module, multimode, LC/UPC-MPO 24 fiber, left exit  
(for MPO module)

- Offers the same craft-friendly interface for LC and SC connectors as the cabled module
- Allow installers to connect an MPO trunk cable to turn up services in rapid installation applications

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber module
<b>Product Brand</b>	NG4access®
<b>Product Series</b>	NG4

## General Specifications

<b>Functionality</b>	Breakout
<b>Application</b>	NG4 MPO module
<b>Adapter Color</b>	Aqua
<b>Adapters, quantity, front</b>	12
<b>Body Style</b>	Duplex
<b>Color, front</b>	Black
<b>Color, housing</b>	Black
<b>Color, rear</b>	Black
<b>Interface, front</b>	LC/UPC
<b>Interface, rear</b>	MPO
<b>Polarity</b>	Method A
<b>Total Fibers, quantity</b>	12
<b>Total Ports, quantity, front</b>	24

## Dimensions

<b>Height</b>	13.21 mm   0.52 in
<b>Width</b>	159.77 mm   6.29 in
<b>Depth</b>	122.68 mm   4.83 in

# NG4-MMDCMOL000

## Outline Drawing



## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM4, bend insensitive

## Environmental Specifications

<b>Operating Temperature</b>	-5 °C to +40 °C (+23 °F to +104 °F)
<b>Storage Temperature</b>	-5 °C to +50 °C (+23 °F to +122 °F)
<b>Relative Humidity</b>	Up to 85%, non-condensing

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Bag   Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

# NG4-MMDCMOL000

---

UK-ROHS

Compliant/Exempted

