

# TFP-5TT00-000B

---

TFP Fiber Termination/Splice Panel, unloaded, termination only rack/cabinet mount panel, 5 RU, 19 in, black, T-handle latch close

## Product Classification

<b>Regional Availability</b>	Asia   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch/splice panel
<b>Product Series</b>	TFP

## General Specifications


<b>Functionality</b>	Patching   Splicing
<b>Body Style</b>	Symmetrical
<b>Color</b>	Black
<b>Color, front</b>	Black
<b>Growth Configuration</b>	Unloaded
<b>Interface, front</b>	Unloaded
<b>Patch Cord Entry Location</b>	Front, left side   Front, right side
<b>Rack Type</b>	EIA 19 in   EIA 23 in
<b>Rack Units</b>	5
<b>Shelf Movement</b>	Fixed

## Dimensions

<b>Height</b>	222.25 mm   8.75 in
<b>Width</b>	482.6 mm   19 in
<b>Depth</b>	399.29 mm   15.72 in

## Ordering Tree

# TFP-5TT00-000B

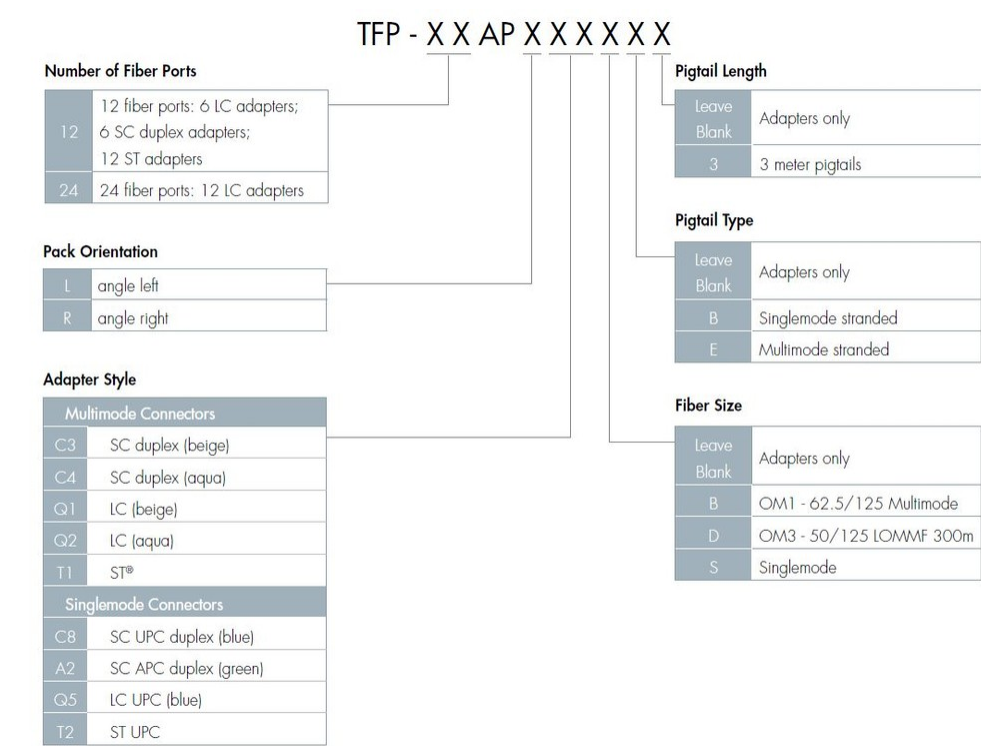

## Material Specifications

Finish	Powder coated
Material Type	Steel

## Environmental Specifications

Operating Temperature	-40 °C to +85 °C (-40 °F to +185 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

## Packaging and Weights

Included	Mounting hardware
Packaging quantity	1
Weight, net	7.194 kg   15.86 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# TFP-5TT00-000B

---

ROHS	Compliant
UK-ROHS	Compliant

