


760243201 | CHD12-DM-12LC-SM-B-ULLM

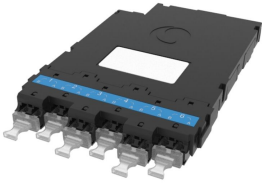

CHD ULL Singlemode MPO-12 distribution module, 12LC to 1x12f MPO pinned, dust plugs

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber module
Product Brand	SYSTIMAX ULL
Product Series	CHD

General Specifications

Functionality	Breakout
Color, front	Blue
Color, rear	Gray
Interface, front	LC/UPC
Interface, rear	MPO
Interface Feature, rear	Key up/up Pinned
Polarity	Method B Enhanced (ULL)
Shuttered	No
Total Fibers, quantity	12

Dimensions

Height	12.45 mm 0.49 in
Width	83.82 mm 3.3 in
Depth	131.83 mm 5.19 in

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

760243201 | CHD12-DM-12LC-SM-B-ULLM

Fiber Type OS2
Insertion Loss, maximum 0.6 dB

Environmental Specifications

Qualification Standards IEC 61753-1 | TIA-568.3-D
Safety Standard CE | CSA | UL

Packaging and Weights

Packaging quantity 1
Weight, net 0.082 kg | 0.18 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
RCM	Compliant to electrical safety & telecommunications requirements
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

