


# DWFMT-5SS208C39D10

---

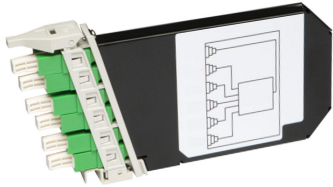

FMT MicroVAM Fiber Optic Module, DWDM, 8 channels, demux, SC /APC, 200GHz channel spacing

## Product Classification

<b>Regional Availability</b>	North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	DWDM module
<b>Product Series</b>	FMT

## General Specifications

<b>Device Type</b>	Micro VAM
<b>Functionality</b>	Demultiplexing
<b>Application</b>	For use with FMT panels   For use with NGF frames
<b>Circuits, quantity</b>	1
<b>Distribution Type</b>	8-channel DWDM
<b>Interface, front</b>	SC/APC
<b>Interface, Input</b>	SC/APC
<b>Interface, Output</b>	SC/APC
<b>Interface, rear</b>	SC/APC
<b>Multiplexers, quantity</b>	1

## Dimensions

<b>Height</b>	71.88 mm   2.83 in
<b>Width</b>	17.27 mm   0.68 in
<b>Depth</b>	177.8 mm   7 in

## Packaging and Weights

# DWFMT-5SS208C39D10

---

**Packaging quantity** 1

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

