


# 760109553 | 360G2 Cartridge 6-SC-SM-BL-PIGTAILS A

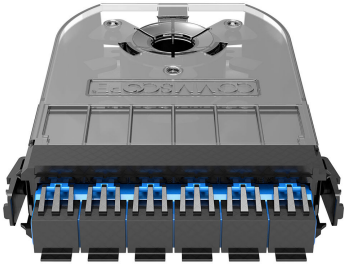

360G2 Singlemode Fiber Cassette 6 SC with pigtails A

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber cassette with pigtails
<b>Product Series</b>	G2

## General Specifications

<b>Color, front</b>	Blue
<b>Intelligence Type</b>	Not iPatch® ready
<b>Interface, front</b>	SC/UPC
<b>Interface, rear</b>	Stranded pigtail
<b>Total Ports, quantity, front</b>	6

## Dimensions

<b>Height</b>	25.908 mm   1.02 in
<b>Width</b>	94.996 mm   3.74 in
<b>Depth</b>	123.012 mm   4.843 in

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A1
<b>Insertion Loss, maximum</b>	0.34 dB

## Environmental Specifications

<b>Qualification Standards</b>	IEC 61753-1   TIA-568.3-D
--------------------------------	---------------------------

# 760109553 | 360G2 Cartridge 6-SC-SM-BL-PIGTAILS A

---

**Safety Standard** CE | CSA | UL

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant