


760109561 | 360G2 Cartridge 6-SC-SM-BL-PIGTAILS B

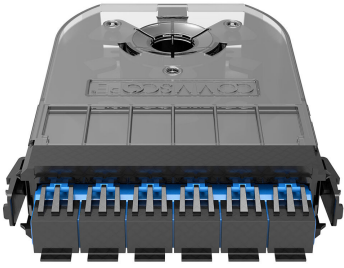

360G2 Singlemode Fiber Cassette 6 SC with pigtails B

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette with pigtails
Product Series	G2

General Specifications

Color, front	Blue
Intelligence Type	Not iPatch® ready
Interface, front	SC/UPC
Interface, rear	Stranded pigtail
Total Ports, quantity, front	6

Dimensions

Height	25.908 mm 1.02 in
Width	94.996 mm 3.74 in
Depth	123.012 mm 4.843 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A1
Insertion Loss, maximum	0.34 dB

Environmental Specifications

Qualification Standards	IEC 61753-1 TIA-568.3-D
--------------------------------	---------------------------

760109561 | 360G2 Cartridge 6-SC-SM-BL-PIGTAILS B

Safety Standard CE | CSA | UL

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant