


CK1334-000 | FIST-GPS2-K-NNN-LM

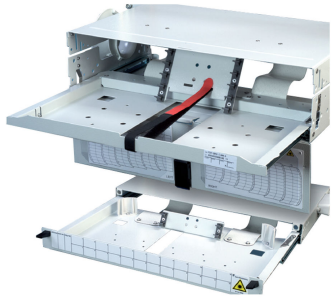

FIST-GPS2 Fiber Panel for holding up to 2 GPST Patch/Splice Trays, unloaded, 1RU, 19 in, gray

Product Classification

Regional Availability	EMEA
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Brand	FIST®
Product Series	FIST-GPS2

General Specifications

Functionality	Patching Splicing
Application	Used in FIST-GR3-style frames only
Color	Gray
Color, front	Gray
Growth Configuration	Unloaded
Rack Type	EIA 19 in ETSI 600 mm
Rack Units	1
Shelf Movement	Sliding

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in

Material Specifications

Finish	Powder coated
Material Type	Galvanized steel

CK1334-000 | FIST-GPS2-K-NNN-LM

Environmental Specifications

Operating Temperature	-5 °C to +45 °C (+23 °F to +113 °F)
Storage Temperature	-30 °C to +60 °C (-22 °F to +140 °F)
Relative Humidity	Up to 93%, non-condensing

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

