

Adapter Pack, Black, 1000-Type, with 6 OptiSPEED® Multimode duplex SC adapters, beige



Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber adapter pack
Product Brand	OptiSPEED®
Product Series	1000-style

General Specifications

Application	Used in conjunction with G2 1U, 2U and 4U adapter panel shelves, surface mount and raised floor enclosures Used in conjunction with panels and enclosures (rack, wall, and floor mount) that accept 1000 style panels
Adapter Color	Beige
Adapter Cutout, quantity	12
Adapters, quantity	6
Body Style	Duplex
Interface	SC/UPC
Pigtails Included, quantity	0
Shuttered	No
Total Ports, quantity	6

Optical Specifications

Fiber Mode	Multimode
-------------------	-----------

Regulatory Compliance/Certifications

Agency	Classification
--------	----------------


760021790 | PNL-BK-012-MFA-SC02-BG

CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant



Included Products

700004880	–	OptiSPEED® SC Duplex Adapter, Beige, Single
MFA-SC02-BG		Pack

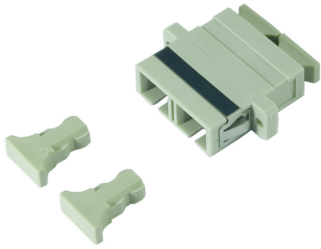

OptiSPEED® SC Duplex Adapter, Beige, Single Pack

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber adapter
Product Brand	OptiSPEED®
Product Series	MFA

General Specifications

Body Style	Duplex
Color	Beige
Interface	SC/UPC
Mounting	Flange
Shuttered	No
Total Ports, quantity	2
Transmission Standards	TIA/EIA-568-B.3 TIA/EIA-604 FOCIS-3

Material Specifications

Alignment Sleeve Material	Phosphorous bronze
----------------------------------	--------------------

Optical Specifications

Fiber Mode	Multimode
-------------------	-----------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value

700004880 | MFA-SC02-BG

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

