


# 760236506 | PNL-CS-12SCX

---

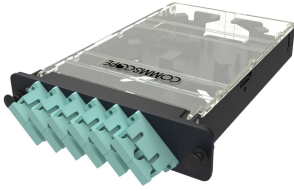

LazrSPEED® Splicing cassette, 12SC , No Pigtails

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber cassette

## General Specifications

<b>Adapter Color</b>	Aqua
<b>Interface, front</b>	SC/UPC
<b>Interface, rear</b>	No pigtail
<b>Total Fibers, quantity</b>	0
<b>Total Ports, quantity, front</b>	6

## Dimensions

<b>Height</b>	28.956 mm   1.14 in
<b>Width</b>	104.648 mm   4.12 in
<b>Depth</b>	165.354 mm   6.51 in

## Optical Specifications

<b>Fiber Mode</b>	Multimode
-------------------	-----------

## Environmental Specifications

<b>Safety Standard</b>	UL
------------------------	----

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
---------------	-----------------------

# 760236506 | PNL-CS-12SCX

---

CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant
UK-ROHS	Compliant

