


XAGA® 550 Copper Closure, unpressurized, heat shrink, 330 mm sheath opening, 90 mm splice bundle diameter

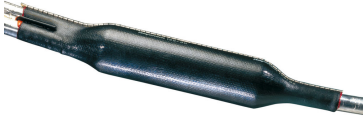

## OBSOLETE

This product was discontinued on: June 30, 2022

## Product Classification

<b>Regional Availability</b>	Latin America
<b>Product Type</b>	Unpressurized heat shrink closure
<b>Product Brand</b>	XAGA®
<b>Product Series</b>	XAGA 550


## General Specifications

<b>Application</b>	For use with Polyethylene and metal jacketed cables
<b>Branch-off Clip</b>	To be ordered separately
<b>Cable Capacity, maximum</b>	3
<b>Cable Sealing Type</b>	Hotmelt adhesive
<b>Closure Style</b>	In-line
<b>Color</b>	Black
<b>Mounting</b>	Duct   Manhole
<b>Splice Protection Type</b>	Metal canister

## Dimensions

<b>Single Cable Diameter, minimum</b>	25 mm   0.984 in
<b>Splice Bundle Diameter, maximum</b>	90 mm   3.543 in
<b>Sheath Opening, nominal</b>	330 mm   12.992 in

## Dimension Drawing

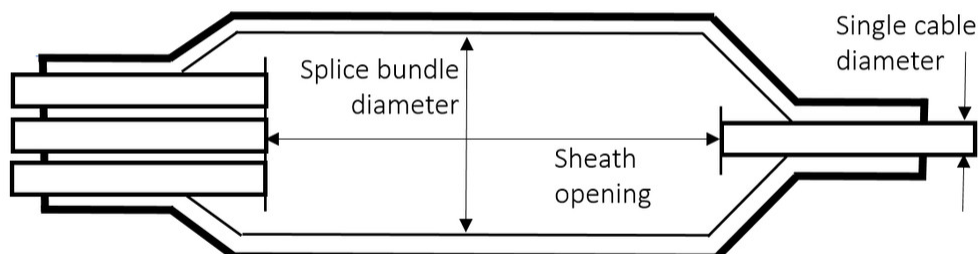

## Material Specifications

**Material Type** Fiber-reinforced multi-layer sealing sleeve

## Environmental Specifications

**Environmental Space** Aerial | Below ground | Buried

## Packaging and Weights

**Included** Abrasive strip | Aluminum closing strip | Aluminum foil | Cleaning tissues | Flexible stainless steel channels | Heatshrinkable sleeve | Metal canister | Shield continuity wire | Underclips

**Packaging quantity** 1

**Packaging Type** Bag | Carton