


FL2-C270024P1-2D02

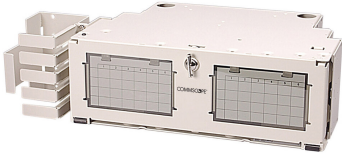

FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 24 SC/UPC, singlemode, 3RU, 23 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	4
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Rack Type	EIA 23 in
Rack Units	3
Shelf Movement	Hinged
Splicing Capacity, maximum	24
Total Ports, quantity	24

Dimensions

Height	133.35 mm 5.25 in
Width	584.2 mm 23 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-C270024P1-2D02

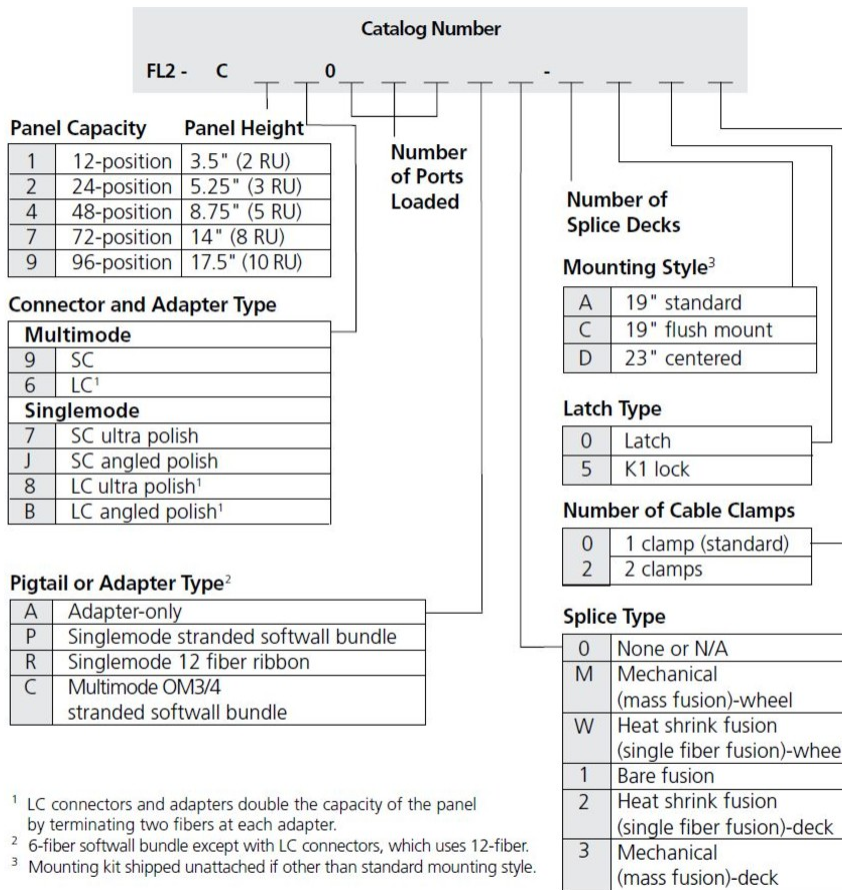

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

FL2-C270024P1-2D02

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

