

FMT-DBS000000-E00P



FMT Fiber Storage Panel, with sliding tray, with storage spools, 1RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber storage panel
Product Series	FMT

General Specifications


Functionality	Slack storage
Body Style	Symmetrical
Color	Black
Color, front	Putty white
Growth Configuration	Unloaded
Interface, front	Unloaded
Patching Capacity, maximum	0
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Splicing Capacity, maximum	0

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in

Ordering Tree

FMT-DBS000000-E00P

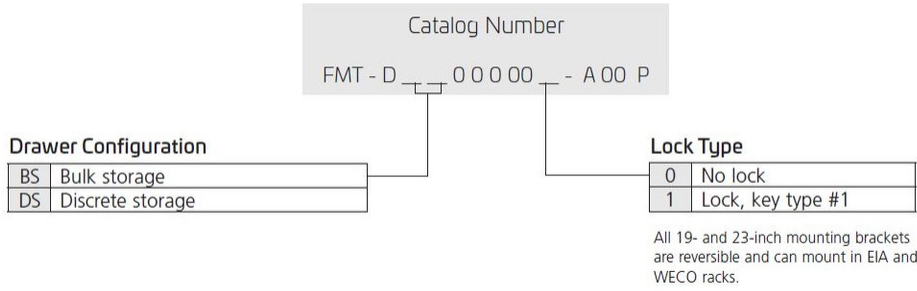

Material Specifications

Finish	Powder coated
Material Type	Steel

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

