

FMT-DDS000000-S00P



FMT Fiber Storage Panel, with sliding tray, with storage trays, 1RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber storage panel
Product Series	FMT

General Specifications


Functionality	Slack storage
Body Style	Symmetrical
Color	Black
Color, front	Putty white
Growth Configuration	Unloaded
Patching Capacity, maximum	0
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Splicing Capacity, maximum	0

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in

Ordering Tree

FMT-DDS000000-SOOP

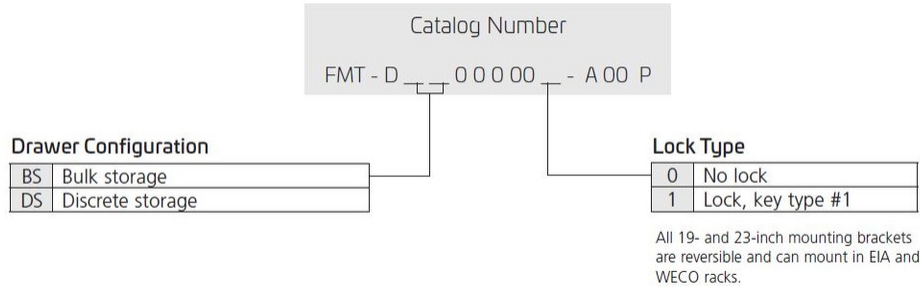

Material Specifications

Finish	Powder coated
Material Type	Steel

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

