


2105067

Base Product

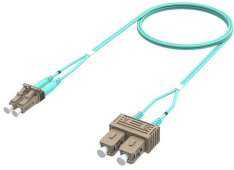

Fiber Optic Patch Cord, OM4, LC/SC Duplex, 1.8mm, LSZH & OFNR, Aqua

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	210

General Specifications


Connector A, quantity	2
Color, boot A	Aqua
Color, connector A	Beige
Connector B, quantity	2
Color, boot B	Aqua
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Polarity	Pairs, flipped
Total Fibers, quantity	2

Dimensions

Cable Assembly Length Range (m)	1 – 50
Diameter Over Jacket	1.8 mm 0.071 in

Ordering Tree

2105067

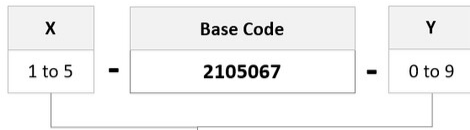

Examples of Lengths (meters)	
-6	6 meters
2- -0	20 meters
2- -5	25 meters
3- -0	30 meters
4- -0	40 meters
5- -0	50 meters

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®
Insertion Loss, maximum 0.3 dB
Return Loss, minimum 27 dB

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Dual Rated LSZH/Riser

Packaging and Weights

Packaging quantity 1