


FAXLCUCOC

Base Product

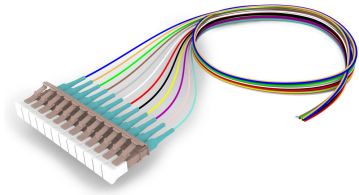

OM4 LC/UPC to Unconnectorized, Fiber Pigtail, 0.9 mm Tight Buffer, 12-Fiber Kit Blue - Aqua (1-12)

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East /Africa | North America

Portfolio

CommScope®

Product Type

Fiber pigtail, unjacketed

Product Brand

SYSTIMAX InstaPATCH® 360

Product Series

FAX

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Aqua

Color, connector A

Beige

Interface, Connector A

LC/UPC

Total Fibers, quantity

12

Dimensions

Cable Assembly Length Range (m)

1 – 20

Cable Assembly Length Range (ft)

1 – 66

Ordering Tree

FAXLCUCOC



Mechanical Specifications

Cable Retention Strength, maximum 1.00 lb @ 0 ° | 1.00 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®
Insertion Loss, maximum, connector A 0.3 dB
Return Loss, minimum, connector A 27 dB

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Unrated

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

460125271 – Behind The Wall Pre-Radiused LC Connector for 0.9 mm Fiber,

FAXLCUCOC

- X-TB-5K
 - multimode
 - LazrSPEED® 900µm Tight Buffered Fiber