


# FBXL8UC11

---

## Base Product

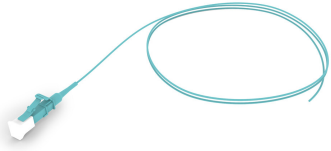

OM4 LC/UPC Keyed Aqua to Unconnectorized, Fiber Pigtail Simplex, 0.9 mm SBJ

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber pigtail, unjacketed
<b>Product Brand</b>	SYSTIMAX InstaPATCH® 360
<b>Product Series</b>	FBX
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


<b>Color, boot A</b>	Aqua
<b>Color, connector A</b>	Aqua
<b>Interface, Connector A</b>	LC/UPC
<b>Interface Feature, connector A</b>	Keyed
<b>Jacket Color</b>	Aqua
<b>Total Fibers, quantity</b>	1

## Dimensions

<b>Cable Assembly Length Range (m)</b>	1 – 20
<b>Cable Assembly Length Range (ft)</b>	1 – 66

## Ordering Tree

# FBXL8UC11

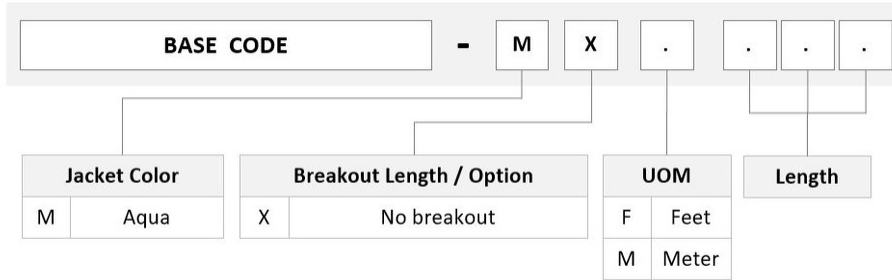

## Mechanical Specifications

**Cable Retention Strength, maximum** 2.00 lb @ 90 ° | 5.00 lb @ 0 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



## Included Products

- 760102582 MFC-LCR-09-KAQ - LazrSPEED®, OptiSPEED® Pre-Radiused Behind The Wall Keyed LC Connector for 0.9 mm Fiber, multimode, aqua
- N-001-RF-5K-F09 - Fiber Indoor Cable, LazrSPEED® 0.9 mm Low Smoke Zero Halogen Reinforced Buffered, 1 fiber, Multimode OM4, Gel-free, Meters jacket marking