


FRXMXLCGD

Base Product

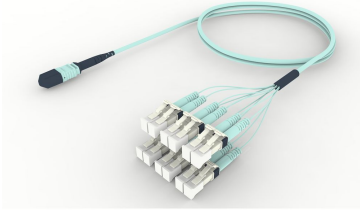

OM4 MPO (Pinned) to LC/UPC, InstaPATCH® 360 Array Cord, 12-Fiber, Low Smoke Zero Halogen

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	Minimum length may vary based on cable configuration Not available in the United States or Canada

General Specifications

Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Aqua
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Method B (LL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions


Cable Assembly Length Range (m)	1 – 305
--	---------

FRXMXLCGD

Cable Assembly Length Range (ft)

1 – 999

Ordering Tree

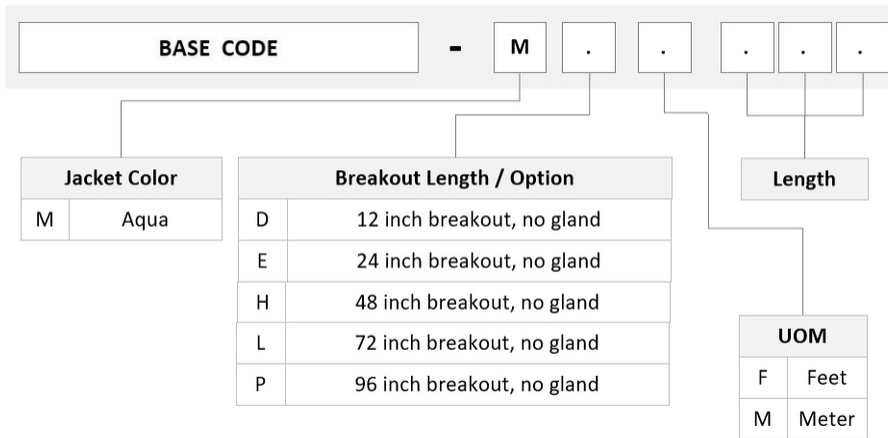

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

FRXMXLCGD



Included Products

- 460125198 – Pre-Radiused LC Connector duplex for 1.6 mm Fiber, multimode
- 760102178 – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO
N-012-MP-5K-F30AQ/D Patchcords, 12 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca flame rating
- 860647047 – MP012, LOW LOSS, MALE, OM3/4, AQUA, 3mm