


# UJGMPMXDF

## Base Product

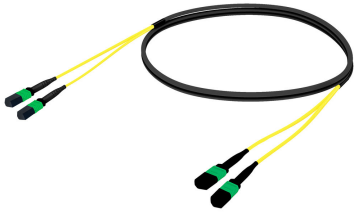

Ultra Low Loss (ULL) Singlemode, MPO12 Unpinned to MPO12 Pinned, Fiber Trunk Cable Assembly, 24-Fiber, Indoor/Outdoor, Low Smoke Zero Halogen/Riser

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Product Brand</b>         | SYSTIMAX ULL   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Color, boot A</b>                | Black                   |
| <b>Color, connector A</b>           | Green                   |
| <b>Color, boot B</b>                | Black                   |
| <b>Color, connector B</b>           | Green                   |
| <b>Construction Type</b>            | Stranded                |
| <b>Furcation Color</b>              | Yellow                  |
| <b>Interface, Connector A</b>       | MPO-12/APC Female       |
| <b>Interface, Connector B</b>       | MPO-12/APC Male         |
| <b>Jacket Color</b>                 | Black                   |
| <b>Polarity</b>                     | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b> | 12                      |
| <b>Total Fibers, quantity</b>       | 24                      |

## Dimensions

# UJGMPMXDF

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 33 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

## Ordering Tree

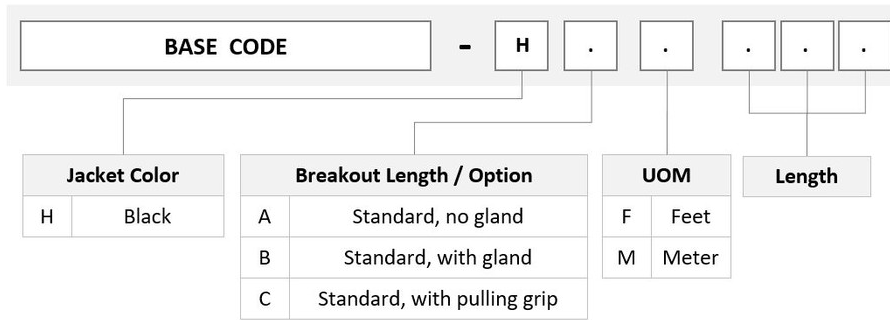

## Mechanical Specifications

|  |                                 |
|--|---------------------------------|
| <b>Cable Retention Strength, maximum</b> | 11.24 lb @ 0 °   4.40 lb @ 90 ° |
|--|---------------------------------|

## Optical Specifications

|                   |                      |
|-------------------|----------------------|
| <b>Fiber Mode</b> | Singlemode           |
| <b>Fiber Type</b> | G.657.A2, TeraSPEED® |

## Environmental Specifications

|                              |  |
|------------------------------|--|
| <b>Operating Temperature</b> | -10 °C to +60 °C (+14 °F to +140 °F)   |
| <b>Environmental Space</b>   | Dual Rated LSZH/Riser   Indoor/Outdoor |

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |



# UJGMPMXDF

---

## Included Products

- 760238826  
Z-024-MP-8G-F12BK/D - Fiber Indoor/Outdoor cable, TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 24 fiber with 12 fiber subunits, Gel-free, Singlemode G.657.A2/B2, Feet jacket marking, Black jacket color, Dca flame rating
- 860638317 - MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm
- 860638318 - MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm