


# UKGMPPMSP

## Base Product

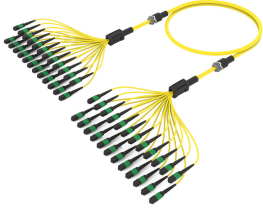

Ultra Low Loss Singlemode MPO12 Unpinned to MPO12 Unpinned 288-Fiber Pre-terminated Trunk Cable, Rollable Ribbon Indoor/Outdoor Armored Central Tube, Low Smoke Zero Halogen/Riser

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America  |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Product Brand</b>         | SYSTIMAX ULL   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |                           |
|-------------------------------------|---------------------------|
| <b>Color, boot A</b>                | Black                     |
| <b>Color, connector A</b>           | Green                     |
| <b>Color, boot B</b>                | Black                     |
| <b>Color, connector B</b>           | Green                     |
| <b>Construction Type</b>            | Armored   Rollable ribbon |
| <b>Furcation Color</b>              | Yellow                    |
| <b>Interface, Connector A</b>       | MPO-12/APC Female         |
| <b>Interface, Connector B</b>       | MPO-12/APC Female         |
| <b>Jacket Color</b>                 | Black                     |
| <b>Polarity</b>                     | Method B Enhanced (ULL)   |
| <b>Fibers per Subunit, quantity</b> | 12                        |
| <b>Total Fibers, quantity</b>       | 288                       |

## Dimensions

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 33 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

# UKGMPMPSP

## Ordering Tree

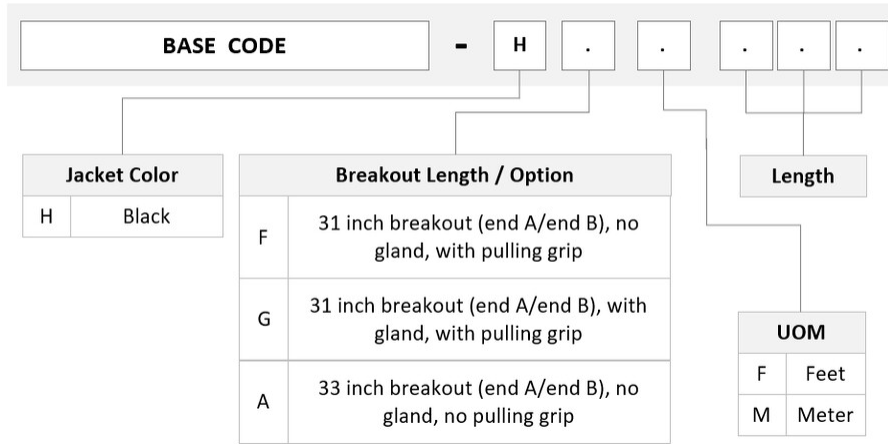

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |

# UKGMPMPSP

---



## Included Products

- 760239049  
Z-288-CZ-RR-F12BK/8G/99G/B2 – Fiber indoor/outdoor cable, Interlocking Armored, LSZH Riser-Rated, Gel-Free, Central Tube Rollable Ribbon, 288 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Black jacket color, B2ca flame rating
- 860638318 – MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm