


# URXQPQPJ8

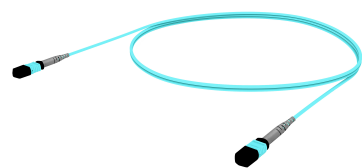

Ultra Low Loss (ULL) OM4 MPO8 (Unpinned) to MPO8 (Unpinned), 8-Fiber, Low Smoke Zero Halogen

## Product Classification

Regional Availability	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration


## General Specifications

Cable Glands	No glands
Color, boot A	Gray
Color, connector A	Aqua
Color, boot B	Gray
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/UPC Female
Interface, Connector B	MPO-08/UPC Female
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	8

## Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	1 – 999

## Ordering Tree

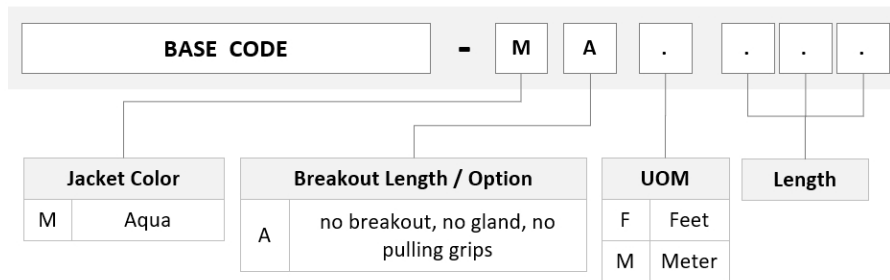

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

<b>Fiber Type</b>	OM4, LazrSPEED®
-------------------	-----------------

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

**Agency**

ANATEL

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS

## Classification

Compliant

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system.

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

Compliant/Exempted

Compliant/Exempted



## Included Products

760102178	-	Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO
N-012-MP-5K-F30AQ/D		Patchcords, 12 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca

# URXQPQPJ8

---

860633307	flame rating
–	MPO8, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm