


DFT-36S024B

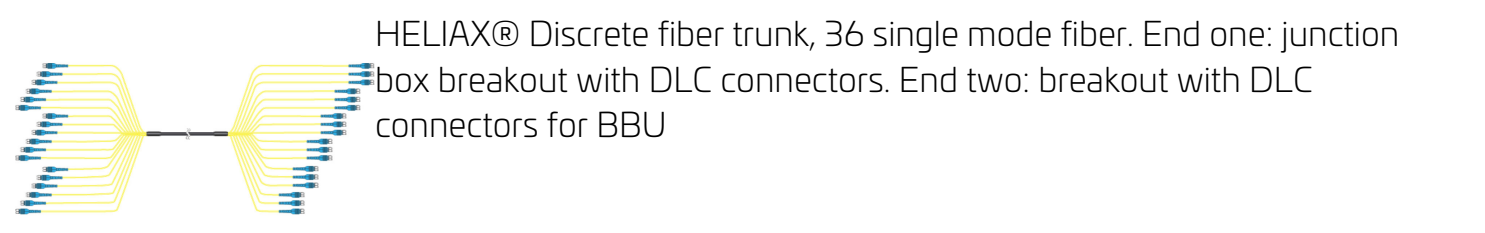

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	DFT
Ordering Note	CommScope® non-standard product

General Specifications


Construction Type	Discrete fiber trunk
Interface, Connector A	LC/UPC
Interface Body Style, connector A	Straight
Interface, Connector B	LC/UPC
Interface Body Style, connector B	Straight
Jacket Color	Black
Total Fibers, quantity	36

Dimensions

Cable Assembly Length Range (ft)	18 – 161
Diameter Over Jacket	11.5 mm 0.453 in

Ordering Tree

DFT-36S024B

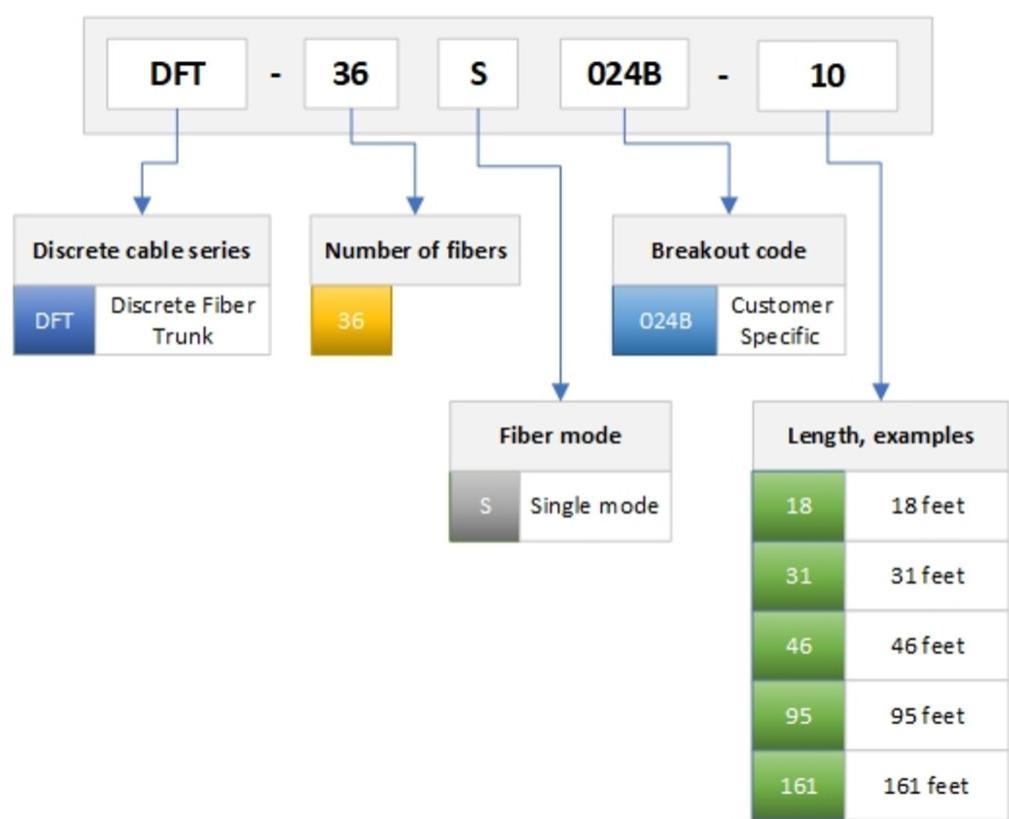

Mechanical Specifications

Minimum Bend Radius	115 mm 4.528 in
Minimum Bend Radius, furcation	30 mm 1.181 in

Optical Specifications

Fiber Type	G.657.A2
Insertion Loss, typical note	Insertion loss is measured at 1310 and 1550 nm
Insertion Loss, typical	0.5

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Environmental Space	Indoor

Packaging and Weights

Cable weight	108 kg/km 72.573 lb/kft
--------------	---------------------------

DFT-36S024B

Regulatory Compliance/Certifications

Agency

ISO 9001:2015



Classification

Designed, manufactured and/or distributed under this quality management system

* Footnotes

Insertion Loss, typical note Insertion loss is measured at a room temp of +20°C (+68°F)