

# TFBM7-3

---

## ION®-B Series Extension Unit for Cellular 700



**OBSOLETE**

### Product Classification

<b>Product Type</b>	Extension unit
<b>Product Brand</b>	ION®-B


### General Specifications

<b>Note</b>	Detailed Product Specifications are available. Please contact your local CommScope representative.
<b>Power Class</b>	Medium

### Dimension Drawing

# TFBM7-3

---

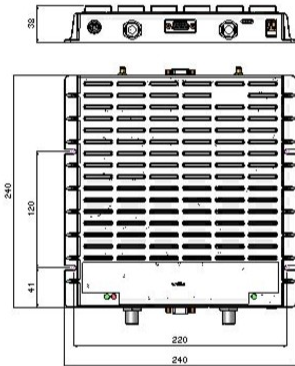

## Electrical Specifications


<b>Impedance</b>	50 ohm
<b>License Band</b>	Cellular 700
<b>Voltage Range</b>	-60 to -36 Vdc

## Electrical Specifications, Tx (Downlink)

<b>Operating Frequency Band</b>	728 – 757 MHz (Cellular 700)
---------------------------------	------------------------------


## Cabling Drawing

# TFBM7-3

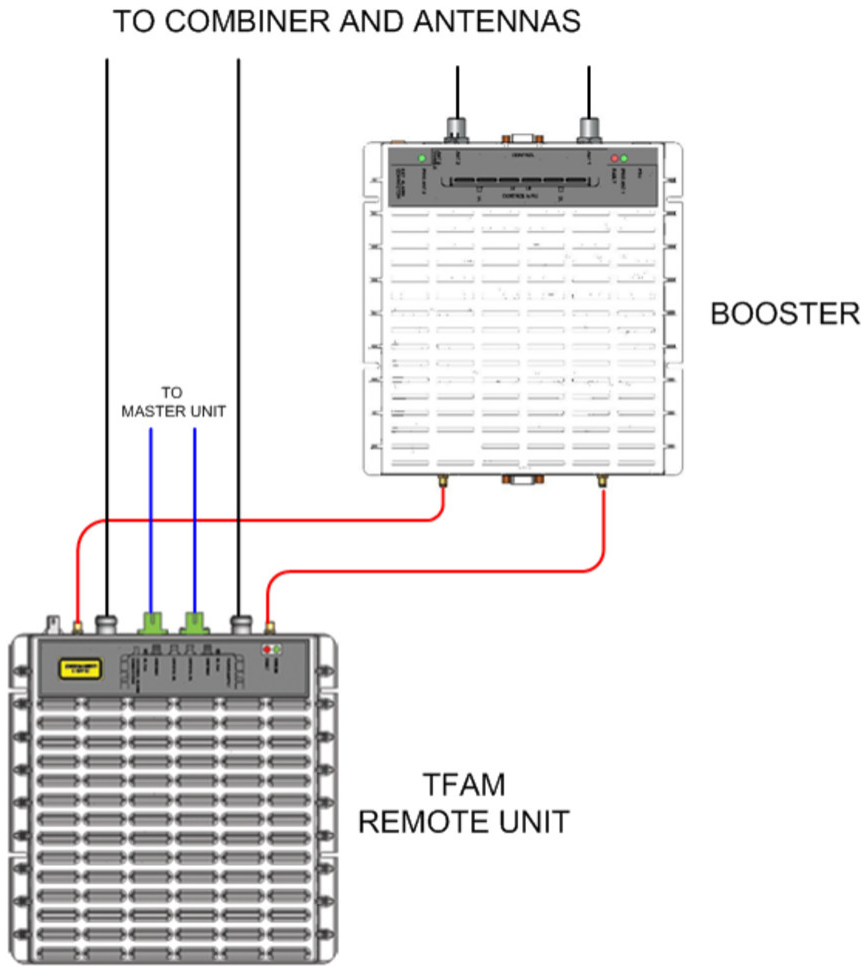

Cabling Drawing 2

# TFBM7-3

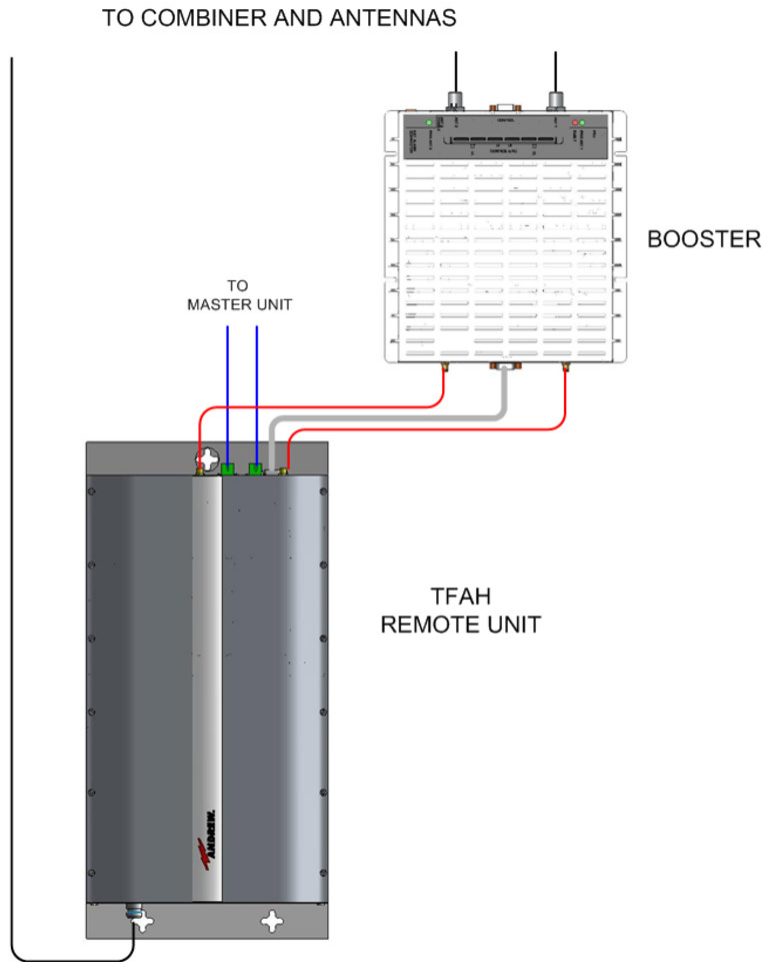

## Regulatory Compliance/Certifications

### Agency

CHINA-ROHS

ISO 9001:2015

ROHS

### Classification

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant/Exempted



## Included Products

- TPSN3/28-80 – Power Supply Adapter ION®-B Series Remote Units, 80 W

# TPSN3/28-80

---

## Power Supply Adapter ION®-B Series Remote Units, 80 W



### Product Classification

**Product Type**

Power adapters

**Product Brand**

ION®-B


### General Specifications

**Note**

Detailed Product Specifications are available. Please contact your local CommScope representative.

### Dimension Drawing

# TPSN3/28-80

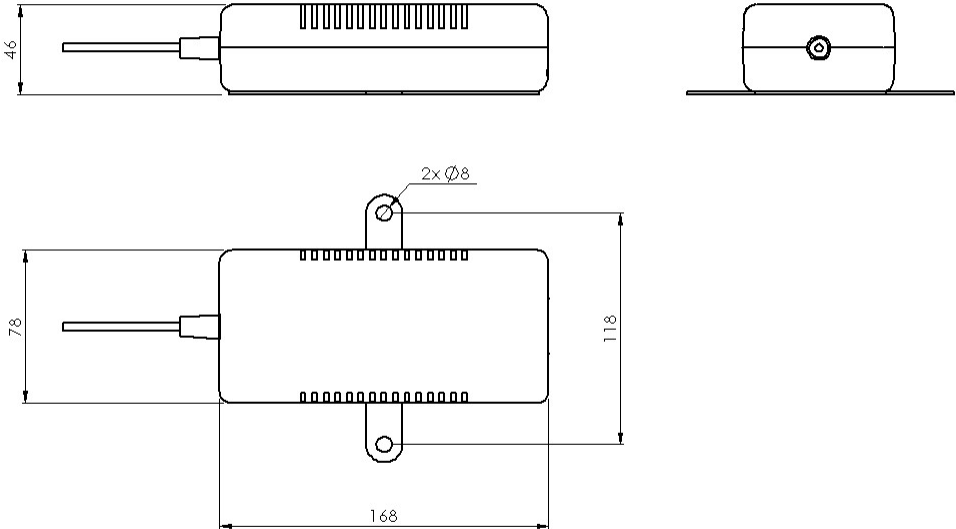

## Electrical Specifications

**Output Power, maximum** 80 W

## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

