

TFAH-EU26/26-34



ION@-B Series High Power Remote Unit MIMO for LTE 2600

OBSOLETE

Product Classification

Product Type	Remote unit
Product Brand	ION@-B

General Specifications

Note	Detailed Product Specifications are available. Please contact your local CommScope representative.
Power Type	High

Electrical Specifications

Impedance	50 ohm
License Band	LTE 2600
Voltage Range	-60 to -38 Vdc

Electrical Specifications, Rx (Uplink)

Operating Frequency Band	2500 – 2570 MHz
---------------------------------	-----------------

Electrical Specifications, Tx (Downlink)

Operating Frequency Band	2620 – 2690 MHz
---------------------------------	-----------------

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

TFAH-EU26/26-34



Included Products

- TPSN3/28-130 - Power Supply Adapter ION®-B Series Remote Units, 130 W

TPSN3/28-130

Power Supply Adapter ION®-B Series Remote Units, 130 W




Product Classification

Product Type	Power adapters
Product Brand	ION®-B

General Specifications

Note	Detailed Product Specifications are available. Please contact your local CommScope representative.
-------------	--

Dimension Drawing

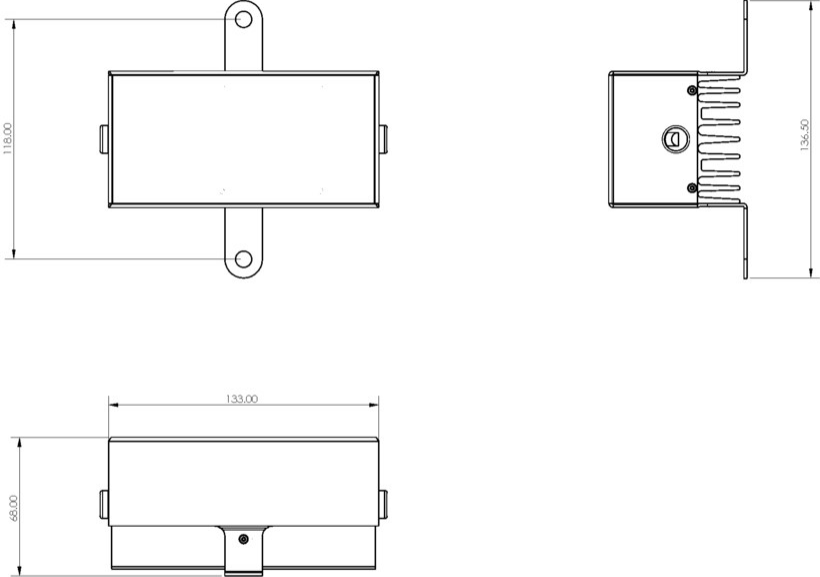

TPSN3/28-130

Electrical Specifications

Output Power, maximum

130 W

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

