


FFWLASA21

Base Product

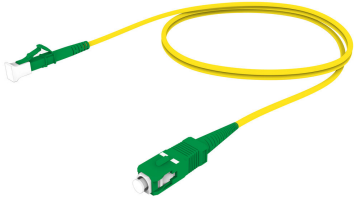

Singlemode LC/APC to SC/APC, Fiber Patch Cord, 1.6 mm Simplex, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber patch cord, simplex
Product Brand	SYSTIMAX InstaPATCH® 360
Product Series	FFW

General Specifications


Connector A, quantity	1
Color, boot A	Green
Color, connector A	Green
Connector B, quantity	1
Color, boot B	Green
Color, connector B	Green
Interface, Connector A	LC/APC
Interface, Connector B	SC/APC
Jacket Color	Yellow
Polarity	Method B
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Diameter Over Jacket	1.6 mm 0.063 in

FFWLASA21

Ordering Tree

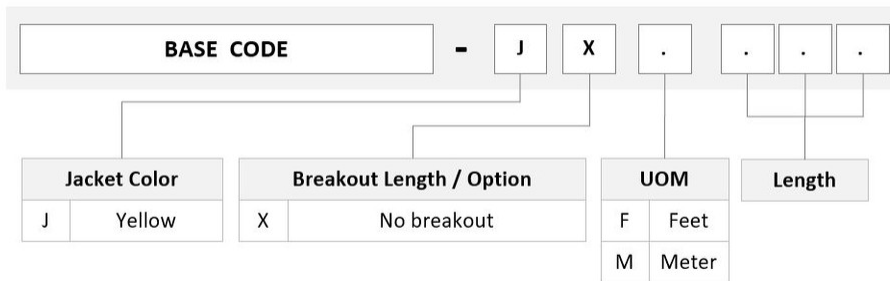

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Operating Temperature, pending approval -20 °C to +70 °C (-4 °F to +158 °F)

Environmental Space Dual Rated LSZH/Riser

Included Products

- 460125784 – TeraSPEED® SC APC Connector for 1.6 mm Fiber, Duplex, Singlemode, green
- 760164160 – Fiber Indoor Cable, OptiSPEED® 1.6mm Low Smoke Zero Halogen Riser, 1-fiber Simplex, Singlemode G.652.D and G.657.A1, Yellow jacket color, Eca Flame Rating
- N-001-SP-8W-F16YL/E
- 860637444 – TeraSPEED® LC/APC Connector for 1.6 mm Fiber, Singlemode, Green, Short Boot