


# 1777268-1 | FPS-OCM-I-F-4U-SHELF

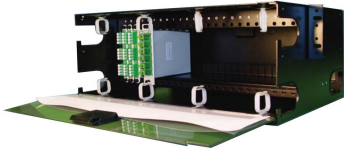

FPS-OCM Front patching shelf, 19" (4RU) with pigtail routing rings, for holding up to 12 OCM1 or 24 OCMF optical modules

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch panel
<b>Product Series</b>	FPS

## General Specifications

<b>Application</b>	Accommodates LGX type modules in a rack environment
<b>Color</b>	Black
<b>Interface, front</b>	Unloaded
<b>Patch Cord Routing</b>	Left sided   Right sided
<b>Rack Type</b>	EIA 19 in
<b>Rack Units</b>	4

## Dimensions

<b>Height</b>	177 mm   6.969 in
<b>Width</b>	465 mm   18.307 in
<b>Depth</b>	483 mm   19.016 in

## Material Specifications

<b>Finish</b>	Powder coated
---------------	---------------

## Packaging and Weights

<b>Included</b>	Label
<b>Packaging quantity</b>	1

## Regulatory Compliance/Certifications

Agency	Classification
--------	----------------

# 1777268-1 | FPS-OCM-I-F-4U-SHELF

---

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

