


760249633

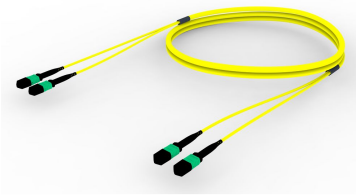

Low Tolerance length Singlemode MPO (Male) to MPO (Male) trunk, 24-Fiber, Low Smoke Zero Halogen B2ca, 290MT

Product Classification

Regional Availability	Europe Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters

General Specifications

Color, boot A	Black
Color, boot B	Black
Color, connector A	Green
Color, connector B	Green
Construction Type	Stranded
Fibers per Subunit, quantity	12
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Male
Interface, Connector B	MPO-12/APC Male
Jacket Color	Yellow
Polarity	Method B (LL)
Total Fibers, quantity	24

Dimensions

Breakout Length	33 in
Cord Length	290 m 951.444 ft
Cable Assembly Length Tolerance	+1/-0 ft

760249633

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant



Included Products

- 760239612 N-024-MP-8W-F12YL/B2 – TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber subunits
- 860366178 – MPO12, LOW LOSS, MALE, Singlemode, GREEN, 3mm