


# UDGSNSNK2

## Base Product

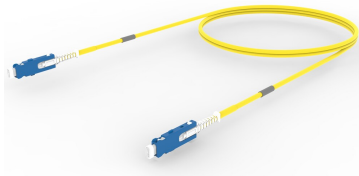

Ultra Low Loss (ULL) Singlemode, SN/UPC to SN/UPC, 2-Fiber, Ruggedized Fanout Cable Plenum

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   EMEA   Europe   India   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Ruggedized fanout
<b>Product Brand</b>	SYSTIMAX ULL
<b>Product Series</b>	UDG
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Color, boot A</b>	Blue
<b>Color, connector A</b>	Blue
<b>Color, boot B</b>	Blue
<b>Color, connector B</b>	Blue
<b>Construction Type</b>	Stranded
<b>Interface, Connector A</b>	SN/UPC
<b>Interface Feature, connector A</b>	ULL
<b>Interface, Connector B</b>	SN/UPC
<b>Interface Feature, connector B</b>	ULL
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced
<b>Total Fibers, quantity</b>	2

## Dimensions

<b>Cable Assembly Length Range (m)</b>	1 – 61
<b>Cable Assembly Length Range (ft)</b>	2 – 200

# UDGSNSNK2

---

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Plenum

## Included Products

- 460201084 – Fiber Optic Connector, SN/UPC for 1.6 mm cable
- 760251282 – Fiber indoor cable, LazrSPEED® Plenum Light Duty Interconnect Cordage, 2 fiber, Multimode OM5, Meters jacket marking, Yellow jacket color
- P-002-DU-8G1-M15YL/AY/LTS