


CL-0610-U

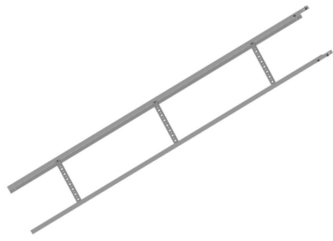

Universal Cable Ladder Kit, 20 in x 10 ft, 6-hole rung

Product Classification

Product Type Ladder kit

General Specifications

Cable Runs, quantity 6

Mounting Round and angle legs

Dimensions


Height 76.2 mm | 3 in

Width 508 mm | 20 in

Length 3048 mm | 120 in

CL-0610-U

Outline Drawing

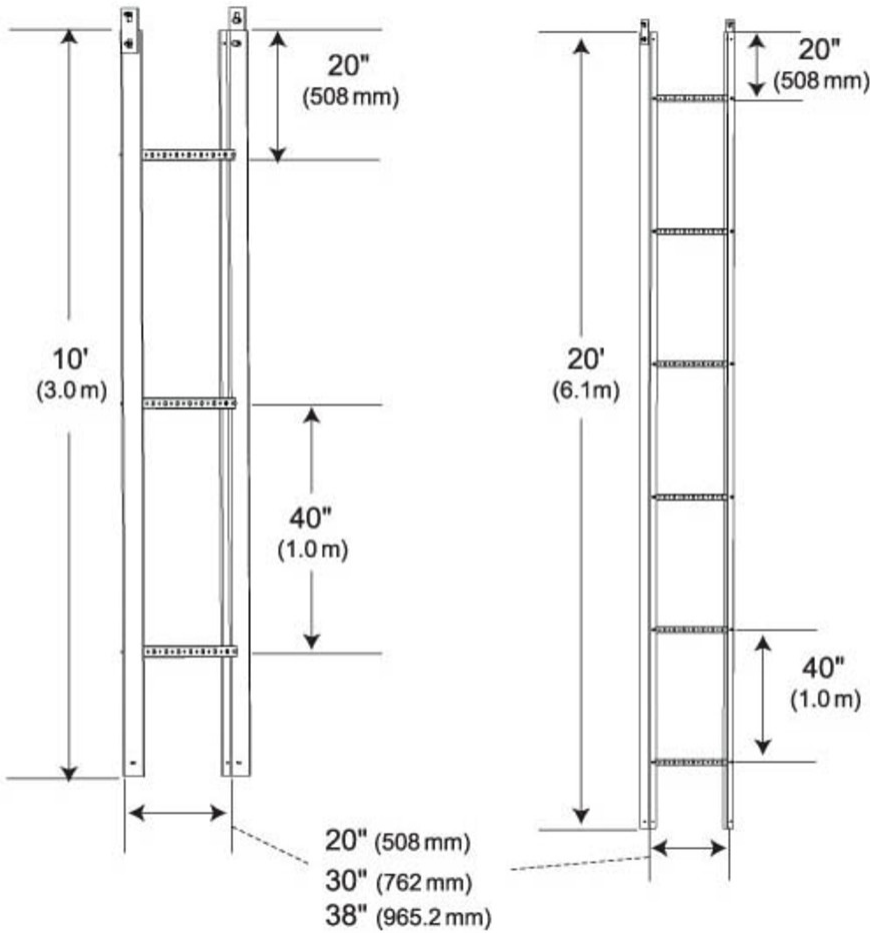

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Attachment kits | Ladder | Splice plates

Packaging quantity 1

Weight, net 25.9 kg | 57.1 lb

Regulatory Compliance/Certifications

Agency **Classification**

CL-0610-U


CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- HK-CL-U – Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

HK-CL-U

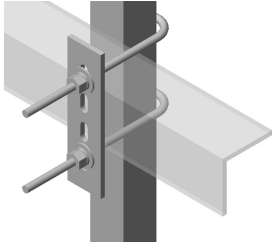

Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

Product Classification

Portfolio	CommScope®
Product Type	Ladder kit
Ordering Note	CommScope® standard product (Global)

General Specifications

Mounting	Round and angle legs
-----------------	----------------------

Dimensions

Height	203.2 mm 8 in
Width	127 mm 5 in
Length	203.2 mm 8 in
Mounting Diameter, maximum	114.3 mm 4.5 in
Mounting Diameter, minimum	25.4 mm 1 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Packaging and Weights

Included	J-bolts Plates
Packaging quantity	1
Weight, net	1.7 kg 3.748 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

HK-CL-U

ROHS

Compliant

UK-ROHS

Compliant

